


前面板 EMC 不锈钢屏蔽套件, for U-Shaped front panels

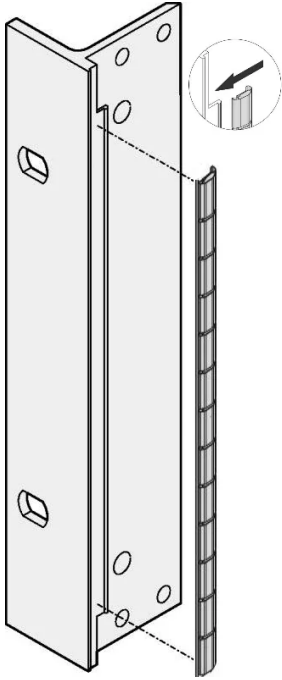

防锈 EMC 垫片可插入 U 型前面板右侧的插槽。

The gasket will be clipped onto the right front panel bracket, the 19" bracket or rear profile of the subrack

功能

不锈钢 EMC 垫片，适用于 SCHROFF U 型前面板，提供卓越的屏蔽效能和广泛的温度范围（从 -200 至 +160°C）。

安装简单——将垫片插入右侧前面板支架，19 英寸支架或插箱的尾型槽

温度范围从 -200 至 +160°C。

技术参数

搭配： 插箱；仪器箱；前面板

产品系列： EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; 框架式插入单元

产品类型： 屏蔽套件


材料： 不锈钢

Table 1/1				
物料号	机架高度	包装数量	机架宽度	快速发货
21102-115	2U	10	10HP	No
21102-105	3U	10		No
21102-106	3U	100	100HP	No
21102-113	4U	10	10HP	No
21102-117	5U	10	10HP	No
21102-107	6U	10	10HP	No
21102-108	6U	100	100HP	No
21102-109	9U	10	10HP	No

其他产品详情

需要防锈的 EMC 垫片来为前面板提供屏蔽防护。

图

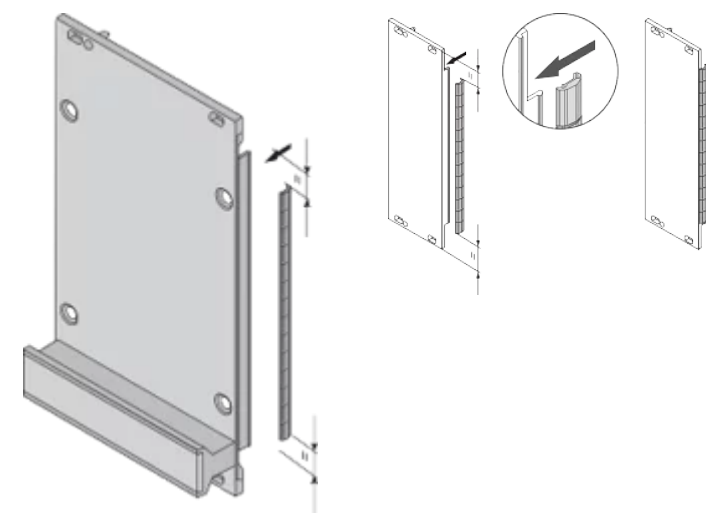

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE