


Front Panel EMC Textile Shielding Kit, -40 up to +70°C

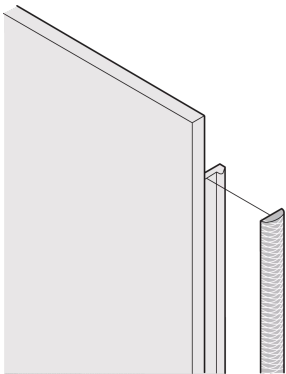

导电布 EMC 屏蔽条，可插入 U 型前面板右侧的插槽。垫片将粘在前面板上。

认证



功能

EMC导电布屏蔽条横向固定在前面板上部或型材右侧的凹槽中，具体视情况而定。

型材密封件，可以粘合到 19" 法兰或后角的接触表面上，实现U 型前面板的导电连接

温度范围 - 40 °C ... +70 °C

技术参数

搭配:	插箱; 仪器箱; 前面板
产品系列:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; 框架式插入单元
产品类型:	屏蔽套件
材料:	热塑性合成橡胶

Table 1/2

物料号	机架高度	包装数量	深度 (D)	高度 (H)	宽度 (W)	可燃性等级
21101-978	5U	10				
21101-857	2U	10	1.62mm	52mm	3.8mm	UL® 94V-0
21101-853	3U	10	1.62mm	97mm	3.8mm	UL® 94V-0
21101-858	4U	10				
21101-854	3U	100	1.62mm	97mm	3.8mm	UL® 94V-0
21101-855	6U	10	1.62mm	232mm	3.8mm	UL® 94V-0
21101-856	6U	100	1.62mm	232mm	3.8mm	UL® 94V-0
21101-904	9U	100				
21101-859	9U	10	1.62mm	365.5mm	3.8mm	UL® 94V-0

Table 2/2


物料号	快速发货
21101-978	No
21101-857	No
21101-853	No
21101-858	No
21101-854	No
21101-855	No

物料号	快速发货
21101-856	No
21101-904	No
21101-859	No

其他产品详情

需要 EMC 导电布垫片来为前面板提供屏蔽防护。

图

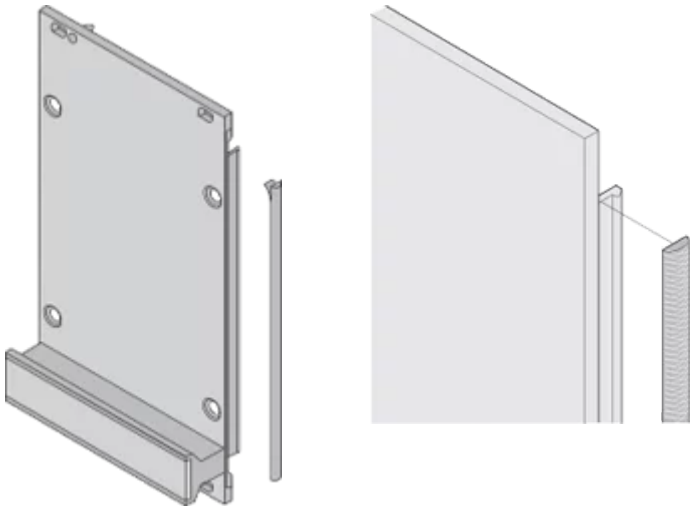

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE