


前面板, 全宽, 开槽, 非屏蔽型, for RatiopacPRO

全宽, 带插槽, 非屏蔽型前面板, 适用于 RatiopacPRO/-AIR。

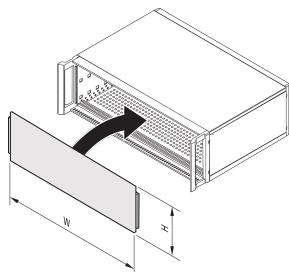

认证



功能

插入侧板和压铸部件之间, 例如饰件, 19" 安装支架或把手

前面板也可用作后面板

无螺钉固定 (特殊水平轨道覆盖前面板的边缘, 并将其保持到位)

屏蔽 (后导电); 如需与机箱导电连接, 请单独订购 EMC 密封 (不锈钢)

技术参数

深度 (D):	2.5mm
材料:	铝
完成:	阳极氧化; 钝化
附件类型:	前面板
产品类型:	前面板

Table 1/2

物料号	机架高度	机架宽度	包装数量	正面表面处理	反面表面处理	边缘处理
-----	------	------	------	--------	--------	------


34571-617	2U	28HP	1	阳极氧化	导电	否
34571-618	2U	42HP	1	阳极氧化	导电	否
34571-605	3U	28HP	1	阳极氧化	导电	否
34571-609	4U	28HP	1	阳极氧化	导电	否
34571-606	3U	42HP	1	阳极氧化	导电	否
34571-619	2U	63HP	1	阳极氧化	导电	否
34571-621	5U	28HP	1	阳极氧化	导电	否
34571-620	2U	84HP	1	阳极氧化	导电	否
34571-610	4U	42HP	1	阳极氧化	导电	否
34571-613	6U	28HP	1	阳极氧化	导电	否
34571-607	3U	63HP	1	阳极氧化	导电	否
34571-622	5U	42HP	1	阳极氧化	导电	否
34571-608	3U	84HP	1	阳极氧化	导电	否
34571-611	4U	63HP	1	阳极氧化	导电	否
34571-614	6U	42HP	1	阳极氧化	导电	否
34571-623	5U	63HP	1	阳极氧化	导电	否
34571-612	4U	84HP	1	阳极氧化	导电	否

34571-615	6U	63HP	1	阳极氧化	导电	否
34571-624	5U	84HP	1	阳极氧化	导电	否
34571-616	6U	84HP	1	阳极氧化	导电	否

Table 2/2			
物料号	高度 (H)	宽度 (W)	快速发货
34571-617	84mm	141.9mm	No
34571-618	84mm	213.2mm	No
34571-605	128.4mm	141.9mm	No
34571-609	172.9mm	141.9mm	No
34571-606	128.4mm	213.2mm	No
34571-619	84mm	319.7mm	No
34571-621	217.3mm	141.9mm	No
34571-620	84mm	426.4mm	No
34571-610	172.9mm	213.2mm	No
34571-613	261.8mm	141.9mm	No
34571-607	128.4mm	319.7mm	No
34571-622	217.3mm	213.2mm	No
34571-608	128.4mm	426.4mm	No

物料号	高度 (H)	宽度 (W)	快速发货
34571-611	172.9mm	319.7mm	No
34571-614	261.8mm	213.2mm	No
34571-623	217.3mm	319.7mm	No
34571-612	172.9mm	426.4mm	No
34571-615	261.8mm	319.7mm	No
34571-624	217.3mm	426.4mm	No
34571-616	261.8mm	426.4mm	No

图

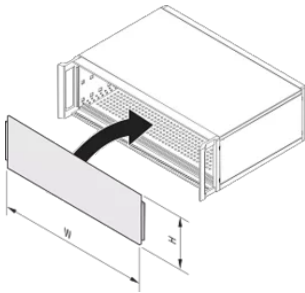

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE