


前面板, U 型, Screwless Mounting for RatiopacPRO Style, 可加装电磁屏蔽功能

前面板无螺丝，前部：阳极氧化，后部：导电；未屏蔽

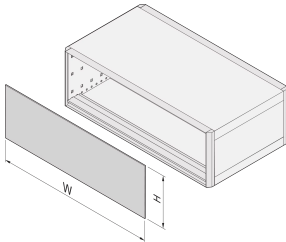

认证



功能

前面板, 铝, 2.5 mm, 前部：阳极氧化, 后部：导电; 非屏蔽

无需螺丝即可安装在水平轨道上

技术参数

材料:	铝
完成:	阳极氧化; 钝化
搭配:	仪器箱
产品类型:	前面板
类型:	前面板
产品系列:	RatiopacPRO 样式; RatiopacPRO

Table 1/1

物料号	机架高度	机架宽度	包装数量	高度	宽度	快速发货
-----	------	------	------	----	----	------

34572-199	2U	28HP	1	84mm	141.9mm	No
34572-203	3U	28HP	1	128.4mm	141.9mm	No
34572-200	2U	42HP	1	84mm	213.2mm	No
34572-207	4U	28HP	1	172.9mm	141.9mm	No
34572-201	2U	63HP	1	84mm	319.7mm	No
34572-204	3U	42HP	1	128.4mm	213.2mm	No
34572-202	2U	84HP	1	84mm	426.4mm	No
34572-208	4U	42HP	1	172.9mm	213.2mm	No
34572-205	3U	63HP	1	128.4mm	319.7mm	No
34572-206	3U	84HP	1	128.4mm	426.4mm	No
34572-209	4U	63HP	1	172.9mm	319.7mm	No
34572-210	4U	84HP	1	172.9mm	426.4mm	No
34572-225	6U	63HP	1	261.8mm	319.7mm	No
34572-226	6U	84HP	1	261.8mm	426.4mm	No
34572-223	6U	28HP	1	261.8mm	141.9mm	No
34572-224	6U	42HP	1	261.8mm	213.2mm	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE