


带螺丝夹的接地/接地母线套件

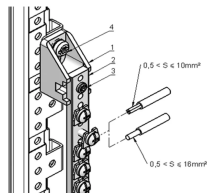

金属条一般安装在开关设备、面板和母线槽机箱内，用于进行局部高电流配电。它们还用于连接电气开关站的高电压设备，以及电池组中的低电压设备。

功能

用螺钉固定, 带出口端或条纹的接地电缆

螺纹固定点 M5, 15 mm 间隔

与框架绝缘的组件

最大电流容量 200 A

技术参数

产品类型: 接地套件

Table 1/1

物料号	长度	材料	包装数量	类型	快速发货
20118-859	200mm	铜	1	螺钉夹	No
20118-865	450mm	铜	1	螺钉夹	No
20118-866	975mm	铜	1	螺钉夹	No
20118-869	2000mm	铜	1	螺钉夹	No

物料号	长度	材料	包装数量	类型	快速发货
20118-868	1900mm	铜	1	螺钉夹	No
20118-867	1680mm	铜	1	螺钉夹	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE