


无头螺钉

用螺钉或铆钉固定到 PCB。

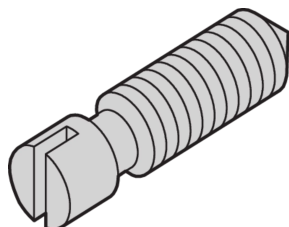

认证



功能

无头螺钉

技术参数

类型: 无头螺钉

产品类型: 螺钉

Table 1/2

物料号	长度	包装数量	螺纹尺寸	完成	材料	产品系列
21100-276	8mm	100	M2.5	镀镍	钢	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO

物料号	长度	包装数量	螺纹尺寸	完成	材料	产品系列
21102-980	8mm	100	M2.5		不锈钢	
21100-646	8mm	100	M3	镀镍	钢	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO

Table 2/2				
物料号	搭配	扭矩	认证	快速发货
21100-276	插箱, 仪器箱, 机箱		RoHS	No
21102-980	插箱, 仪器箱, 机箱	0.37N • m		No
21100-646	插箱, 仪器箱, 机箱		RoHS	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书。或咨询你的 nVent

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE