


Guide Rail With Coding for CompactPCI/ VME64x, Offset 0.1", PC

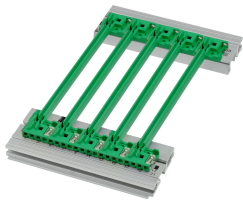

New generation of With Coding, Offset type guide rails for PCBs or plug-in units. Forms a reliable interface between the subrack mechanics and the sub-assemblies. With the optimized design and the new high quality plastic material not just the stability was significantly increased, but also the fire safety properties improved. Which means the material ensures a low flammability, low smoke toxicity and density and fulfills the EN 45545-2 (Fire Safety in Railway Vehicle) requirements sets R22, R23 and R24 with the

认证



功能

新一代编码型, 偏置型塑料导轨, 实现 PCB 或插入式装置的可靠固定

稳定性显著提高, 得益于优化设计和高质量材料 (PC)

提高防火安全性能, 符合 EN 45545-2 规范 R22, R23 和 R24 中的最高危险等级 HL3

“无卤素”, 符合 IEC 61249-2-21 标准

导轨可以卡入水平横梁 (铝挤压件) 或 1.5 mm 厚板中

可以通过螺栓固定到 H 型和 R 型水平横梁, 以满足更高的抗冲击和振动要求

可选 ESD 夹, 用于 PCB 和水平横梁之间的导电触点

存储温度: 从 -40 °C.. 130 °C

技术参数

搭配: 插槽; 仪器箱; 19" 机箱; 系统

类型: 编码, 偏移

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac

材料: 纤维增强型塑料

颜色: 绿色

产品类型: 导轨

Table 1/1					
物料号	包装数量	板深度	槽宽	符合	快速发货
64568-071	1	160mm	2	EN 45545-2	No
24568-359	10	160mm	2	EN 45545-2	No
64568-072	1	220mm	2	EN 45545-2	No

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	Emirates
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE