


水平轨道螺母条, M2.5

螺母条是一种带 M2.5 螺纹的金属条，可用于固定前面板。

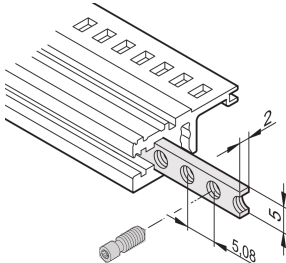

认证



功能

用于固定部分宽度前面板的凸缘螺钉，必须是 12.3 mm 长

适用于所有水平横梁

技术参数

搭配: 插箱; 仪器箱

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac

材料: 钢

产品类型: 螺纹嵌件

完成: 镀锌

Table 1/1

物料号	机架宽度	包装数量	长度	快速发货
34561-328	28HP	1	146.82mm	No

物料号	机架宽度	包装数量	长度	快速发货
34561-342	42HP	1	217.94mm	No
34561-363	84HP	1	324.62mm	No
34561-384	84HP	1	431.3mm	No
34565-196	196HP	1	1000.26mm	No
34561-320	20HP	1	106.18mm	No
34561-340	40HP	1	207.78mm	No

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	Emirates
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE