


# Intermediate Adapter to Assemble Several 3 U Testadapter

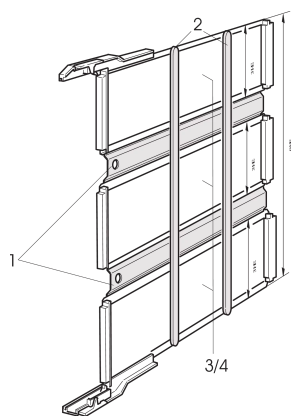

支架套件，可基于 3 U 测试转接卡制作 6/9 U 测试转接卡。适合带 DIN 41612 连接器的 B、C、E 和 F 型测试转接卡。

## 认证



## 功能

适用 B, C, D, E, F

## 技术参数

Table 1/1

| 物料号       | 搭配    | 材料 | 包装数量 | 完成   | 快速发货 |
|-----------|-------|----|------|------|------|
| 20800-224 | 测试适配器 | 钢  | 2    | 粉末涂层 | No   |
| 20800-168 | 测试适配器 | 钢  | 2    | 粉末涂层 | No   |

| 物料号       | 搭配    | 材料 | 包装数量 | 完成   | 快速发货 |
|-----------|-------|----|------|------|------|
| 20800-278 | 测试适配器 | 钢  | 2    | 粉末涂层 | No   |
| 20800-279 | 测试适配器 | 钢  | 2    | 粉末涂层 | No   |
| 23040-001 | 测试适配器 | 钢  | 2    | 粉末涂层 | No   |

其他产品详情

适合 D 型 DIN 连接器的测试转接卡无法与其他类型转接卡卡结合使用。

VMEbus 测试转接卡深度（尺寸 B）位于相应产品页面。

B、C、D、E、F 型测试转接卡深度（尺寸 B）位于相应产品页面

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE