


带风扇的 Interscale 风扇架

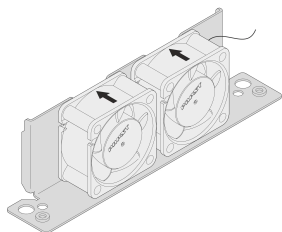

带风扇的 Interscale 风扇支架，适用于桌面式机箱和 19" 机箱。提供不同尺寸和三种风扇版本，风量从 10 至 170 立方米/小时。

功能

安装在机箱底部的风扇支架

使用减振固定材料将风扇轻松安装到风扇支架上

风扇支架用 2 个塑料支脚固定到桌面式机箱或用 2 个螺钉固定到 19" 机箱中

风扇支架不能与安装板一起使用（而是使用带有集成风扇支架的安装板）

有关风扇的技术数据, 请参阅交货单

技术参数

完成: 镀锌铝
类型: 风扇盘
产品类型: 风扇单元
直流输入电压: 12V min

Table 1/2

物料号	宽度	深度	包装数量	最大静压	最大环境温度	气流
24830-101	80mm	25mm	1	95.41Pa	70°C	109m ³ /h
24828-104	40mm	20mm	1		70°C	10m ³ /h

物料号	宽度	深度	包装数量	最大静压	最大环境温度	气流
24830-102	80mm	25mm	1			
24828-105	40mm	20mm	1		70°C	10m³/h
24828-204	80mm	25mm	1		70°C	19m³/h
24828-205	80mm	25mm	1		70°C	19m³/h
24828-107	40mm	20mm	1		70°C	10m³/h
24828-305	119mm	25mm	1		70°C	170m³/h
24828-207	80mm	25mm	1		70°C	19m³/h
24828-307	119mm	25mm	1		70°C	170m³/h

Table 2/2						
物料号	噪音等级	高度	材料	电源	产品系列	快速发货
24830-101	44.62dB(A)	80mm	钢			No
24828-104	18dB(A)	40mm	钢	0.9W	Interscale	No
24830-102		80mm	钢			No
24828-105	18dB(A)	40mm	钢	0.9W	Interscale	No
24828-204	32dB(A)	80mm	钢	2W	Interscale	No
24828-205	32dB(A)	80mm	钢	2W	Interscale	No
24828-107	18dB(A)	40mm	钢	0.9W	Interscale	No

物料号	噪音等级	高度	材料	电源	产品系列	快速发货
24828-305	43dB(A)	119mm	钢	5.3W	Interscale	No
24828-207	32dB(A)	80mm	钢	2W	Interscale	No
24828-307	43dB(A)	119mm	钢	5.3W	Interscale	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE