


用于 PCB 的 Interscale 安装板

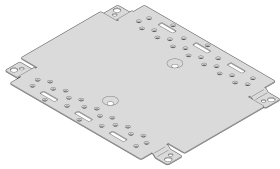

Interscale 安装板，用于将 PCB 固定在小尺寸桌面式机箱和 19" 机箱中。

功能

带有集成风扇支架的安装板（抬高 4 mm), 风扇套件支持开有通风孔的机箱

使用减振固定材料, 可将风扇轻松安装到安装板上

不适用于嵌入式 NUC 和 19" 的 Interscale M

技术参数

完成:	镀锌铝
产品系列:	Interscale
产品类型:	安装板
类型:	安装板
搭配:	小尺寸机箱
材料:	钢

Table 1/1

物料号	宽度	深度	包装数量	高度	快速发货
24822-095	399mm	221mm	1	1mm	No
24822-033	133mm	133mm	1	1mm	No
24822-005	444mm	221mm	1	1mm	No

物料号	宽度	深度	包装数量	高度	快速发货
24822-054	221mm	177mm	1	1mm	No
24822-075	310mm	221mm	1	1mm	No
24822-007	444mm	310mm	1	1mm	No
24822-055	221mm	221mm	1	1mm	No
24822-097	399mm	310mm	1	1mm	No
24822-034	133mm	177mm	1	1mm	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE