


# MultipacPRO 19" 机箱基本套件

该套件便于客户配置 3 种不同的顶/底盖板。

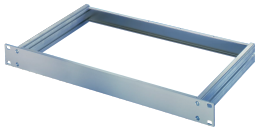

## 认证



## 功能

适用于非标准化组件 (1 ... 5 U) 和标准化组件 (1, 2 U)，符合 IEC 60297-3-105 标准

框架包括两个侧板和前/后面板

材料：铝

选择其他组件（附件）

## 技术参数

|         |             |
|---------|-------------|
| 材料:     | 铝           |
| 类型:     | 可配置         |
| 产品系列:   | MultipacPRO |
| EMC 屏蔽: | 无（可改装）      |
| 产品类型:   | 插箱/机箱       |

Table 1/2

| 物料号 | 机架高度 | 深度 | 可用宽度 | 安装 | 符合 | 认证 |
|-----|------|----|------|----|----|----|
|-----|------|----|------|----|----|----|

|           |    |       |       |    |                 |      |
|-----------|----|-------|-------|----|-----------------|------|
| 20860-201 | 1U | 220mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-202 | 1U | 280mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-203 | 1U | 340mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-204 | 1U | 400mm | 403mm | 机架 | IEC 60297-3-100 |      |
| 20860-205 | 1U | 460mm | 403mm | 机架 | IEC 60297-3-100 |      |
| 20860-210 | 2U | 220mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-231 | 4U | 460mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-211 | 2U | 280mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-212 | 2U | 340mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-213 | 2U | 400mm | 403mm | 机架 | IEC 60297-3-100 |      |
| 20860-214 | 2U | 460mm | 403mm | 机架 | IEC 60297-3-100 |      |
| 20860-219 | 3U | 280mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-220 | 3U | 340mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-221 | 3U | 400mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-228 | 4U | 280mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-222 | 3U | 460mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-229 | 4U | 340mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |

|           |    |       |       |    |                 |      |
|-----------|----|-------|-------|----|-----------------|------|
| 20860-230 | 4U | 400mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |
| 20860-240 | 5U | 460mm | 403mm | 机架 | IEC 60297-3-100 | RoHS |

| Table 2/2 |      |
|-----------|------|
| 物料号       | 快速发货 |
| 20860-201 | No   |
| 20860-202 | No   |
| 20860-203 | No   |
| 20860-204 | No   |
| 20860-205 | No   |
| 20860-210 | No   |
| 20860-231 | No   |
| 20860-211 | No   |
| 20860-212 | No   |
| 20860-213 | No   |
| 20860-214 | No   |
| 20860-219 | No   |
| 20860-220 | No   |
| 20860-221 | No   |

| 物料号       | 快速发货 |
|-----------|------|
| 20860-228 | No   |
| 20860-222 | No   |
| 20860-229 | No   |
| 20860-230 | No   |
| 20860-240 | No   |

其他产品详情

请单独订购安装板、盖板和底板、把手、伸缩滑轨。

尺寸 h = 净安装高度 = H - 8.1 mm，b = 净安装宽度 = 403 mm。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

| North America                                                                                                 | Europe                                                                                                                                                                                                                                     | Asia                                                                                                                                                                                                                             | Middle East & India                                                                                                                                                                                            |
|---------------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| All locations<br>+1.763.422.2661<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> | Straubenhardt, Germany<br>+49.7082.794.0<br>Betschdorf, France<br>+33.3.88.90.64.90<br>Warsaw, Poland<br>+48.22.209.98.35<br>Assago, Italy<br>+39.02.932.7141<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> | Shanghai, China<br>+86.21.2412.6943<br>Qingdao, China<br>+86.532.8771.6101<br>Singapore<br>+65.6768.5800<br>Shin-Yokohama, Japan<br>+81.45.476.0271<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> | Dubai, United Arab<br>Emirates<br>+971.4.378.1700<br>Bangalore, India<br>+91.80.6715.2001<br>Istanbul, Turkey<br>+90.216.250.7374<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> |



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE