


Novastar 19" 角轨

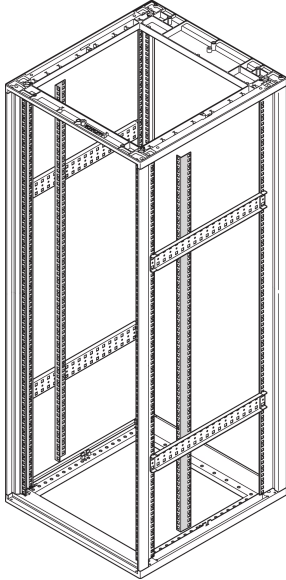

Novastar 19" 面板/滑轨安装套件，承载能力 400 kg，可确保轻松将 19" 组件安装至埋深构件。

认证



功能

用于 19" 组件嵌入式安装

用于安装到深度支撑上（25 mm间隔）

承载能力 400 千克

技术参数

产品类型： 滑动安装座

材料： 钢

Table 1/2

物料号	机架高度	包装数量	颜色	颜色代码	完成	高度
27230-172	6U	2	暗灰色	RAL 7021	粉末涂层	267.1mm
27230-173	9U	2	暗灰色	RAL 7021	粉末涂层	400.45mm
27230-174	12U	2	暗灰色	RAL 7021	粉末涂层	533.8mm
27230-175	16U	2	暗灰色	RAL 7021	粉末涂层	711.6mm
27230-176	20U	2	暗灰色	RAL 7021	粉末涂层	889.4mm
27230-177	25U	2	暗灰色	RAL 7021	粉末涂层	1111.65mm
27230-197	29U	2	暗灰色	RAL 7021	粉末涂层	1291mm
27230-178	34U	2	暗灰色	RAL 7021	粉末涂层	1511.7mm
27230-179	38U	2	暗灰色	RAL 7021	粉末涂层	1689.5mm
27230-180	43U	2	暗灰色	RAL 7021	粉末涂层	1911.75mm
27230-181	47U	2	暗灰色	RAL 7021	粉末涂层	2089.55mm

Table 2/2

物料号	包装单位	认证	快速发货
27230-172	对	RoHS	No
27230-173	对	RoHS	No
27230-174	对	RoHS	No
27230-175	对	RoHS	No

物料号	包装单位	认证	快速发货
27230-176	对	RoHS	No
27230-177	对	RoHS	No
27230-197			No
27230-178	对	RoHS	No
27230-179	对	RoHS	No
27230-180	对	RoHS	No
27230-181	对	RoHS	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE