


Novastar 基座/底座

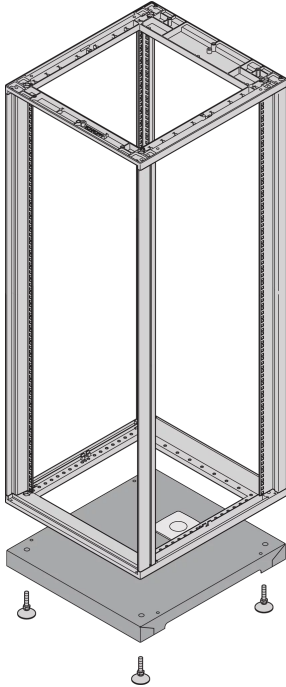

后电缆j进出线的底板，带有开孔，用于电缆管理。开口包覆有塑料。附件刷条可以置于其中。

认证



功能

静态承载能力 400 千克

可调节支脚, 高度 57 mm ... 67 mm

碳钢, 1.5 mm, RAL 7021

电缆管道 110 x 76 mm

包括接地部件

可调支脚

静态承重能力400 kg

技术参数

高度: 45mm

产品类型: 机柜/机架底座

材料: 钢

Table 1/2						
物料号	宽度	深度	包装数量	颜色	颜色代码	完成
27230-070	553mm	500mm	1	暗灰色	RAL 7021	粉末涂层
27230-072	553mm	800mm	1	暗灰色	RAL 7021	粉末涂层
27230-080	1000mm	1000mm	1	暗灰色	RAL 7021	粉末涂层
27230-076	900mm	900mm	1	暗灰色	RAL 7021	粉末涂层
27230-071	553mm	600mm	1	暗灰色	RAL 7021	粉末涂层

Table 2/2		
物料号	类型	快速发货
27230-070	底座	No
27230-072	底座	No
27230-080	底座	No
27230-076	底座	No
27230-071	底座	No

其他产品详情

请单独订购刷条。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE