


适用于 Slim-Line 的 Novastar 侧面板

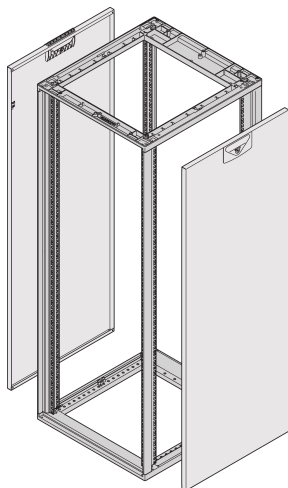

适用于轻型

铝框架的钢侧板，带快拆锁扣，便于安装和装配。SCHROFF 提供保护层套件，包括已安装且经过测试的接地电缆

认证



功能

带四分之一转紧固件的侧面板, 包括接地

碳钢, 1 mm

技术参数

产品类型: 机柜/机架面板

材料: 钢

Table 1/2

物料号	机架高度	高度	深度	包装数量	颜色	颜色代码
26230-173	16U	709mm	800mm	2	浅灰色	RAL 7035

物料号	机架高度	高度	深度	包装数量	颜色	颜色代码
26230-136	43U	1909mm	1000mm	2	浅灰色	RAL 7035
26230-137	47U	2087mm	900mm	2	浅灰色	RAL 7035
26230-138	47U	2087mm	1000mm	2	浅灰色	RAL 7035
26230-172	12U	589mm	800mm	2	浅灰色	RAL 7035
26230-174	20U	945mm	800mm	2	浅灰色	RAL 7035
26230-175	25U	1167mm	800mm	2	浅灰色	RAL 7035
26230-176	34U	1567mm	800mm	2	浅灰色	RAL 7035
26230-177	38U	1745mm	800mm	2	浅灰色	RAL 7035
26230-178	43U	1967mm	800mm	2	浅灰色	RAL 7035
26230-179	47U	2145mm	800mm	2	浅灰色	RAL 7035
25230-160	29U	1345mm	500mm	2	暗灰色	RAL 7021
25230-161	29U	1345mm	600mm	2	暗灰色	RAL 7021
25230-162	29U	1345mm	800mm	2	暗灰色	RAL 7021
25230-163	29U	1345mm	900mm	2	暗灰色	RAL 7021
25230-164	29U	1345mm	1000mm	2	暗灰色	RAL 7021
26230-160	29U	1345mm	500mm	2	浅灰色	RAL 7035
26230-161	29U	1345mm	600mm	2	浅灰色	RAL 7035

物料号	机架高度	高度	深度	包装数量	颜色	颜色代码
26230-162	29U	1345mm	800mm	2	浅灰色	RAL 7035
26230-163	29U	1345mm	900mm	2	浅灰色	RAL 7035
26230-164	29U	1345mm	1000mm	2	浅灰色	RAL 7035
25230-070	6U	357mm	500mm	2	暗灰色	RAL 7021
25230-071	9U	490mm	500mm	2	暗灰色	RAL 7021
25230-072	12U	589mm	500mm	2	暗灰色	RAL 7021
25230-073	16U	709mm	500mm	2	暗灰色	RAL 7021
25230-074	20U	945mm	500mm	2	暗灰色	RAL 7021
25230-075	25U	1167mm	500mm	2	暗灰色	RAL 7021
25230-076	34U	1567mm	500mm	2	暗灰色	RAL 7021
25230-077	38U	1745mm	500mm	2	暗灰色	RAL 7021
25230-078	43U	1967mm	500mm	2	暗灰色	RAL 7021
25230-079	47U	2145mm	500mm	2	暗灰色	RAL 7021
25230-113	12U	531mm	900mm	2	暗灰色	RAL 7021
25230-114	12U	531mm	1000mm	2	暗灰色	RAL 7021
25230-115	16U	709mm	900mm	2	暗灰色	RAL 7021
25230-116	16U	709mm	1000mm	2	暗灰色	RAL 7021

物料号	机架高度	高度	深度	包装数量	颜色	颜色代码
25230-117	20U	887mm	900mm	2	暗灰色	RAL 7021
25230-118	20U	887mm	1000mm	2	暗灰色	RAL 7021
25230-119	25U	1109mm	900mm	2	暗灰色	RAL 7021
25230-120	6U	357mm	600mm	2	暗灰色	RAL 7021
25230-121	9U	490mm	600mm	2	暗灰色	RAL 7021
25230-122	12U	589mm	600mm	2	暗灰色	RAL 7021
25230-123	16U	709mm	600mm	2	暗灰色	RAL 7021
25230-124	20U	945mm	600mm	2	暗灰色	RAL 7021
25230-125	25U	1167mm	600mm	2	暗灰色	RAL 7021
25230-126	34U	1567mm	600mm	2	暗灰色	RAL 7021
25230-127	38U	1745mm	600mm	2	暗灰色	RAL 7021
25230-128	43U	1967mm	600mm	2	暗灰色	RAL 7021
25230-129	47U	2145mm	600mm	2	暗灰色	RAL 7021
25230-130	25U	1109mm	1000mm	2	暗灰色	RAL 7021
25230-131	34U	1509mm	900mm	2	暗灰色	RAL 7021
25230-132	34U	1509mm	1000mm	2	暗灰色	RAL 7021
25230-133	38U	1687mm	900mm	2	暗灰色	RAL 7021

物料号	机架高度	高度	深度	包装数量	颜色	颜色代码
25230-134	38U	1687mm	1000mm	2	暗灰色	RAL 7021
25230-135	43U	1909mm	900mm	2	暗灰色	RAL 7021
25230-136	43U	1909mm	1000mm	2	暗灰色	RAL 7021
25230-137	47U	2087mm	900mm	2	暗灰色	RAL 7021
25230-138	47U	2087mm	1000mm	2	暗灰色	RAL 7021
25230-172	12U	589mm	800mm	2	暗灰色	RAL 7021
25230-173	16U	709mm	800mm	2	暗灰色	RAL 7021
25230-174	20U	945mm	800mm	2	暗灰色	RAL 7021
25230-175	25U	1167mm	800mm	2	暗灰色	RAL 7021
25230-176	34U	1567mm	800mm	2	暗灰色	RAL 7021
25230-177	38U	1745mm	800mm	2	暗灰色	RAL 7021
25230-178	43U	1967mm	800mm	2	暗灰色	RAL 7021
25230-179	47U	2145mm	800mm	2	暗灰色	RAL 7021
26230-070	6U	357mm	500mm	2	浅灰色	RAL 7035
26230-071	9U	490mm	500mm	2	浅灰色	RAL 7035
26230-072	12U	589mm	500mm	2	浅灰色	RAL 7035
26230-073	16U	709mm	500mm	2	浅灰色	RAL 7035

物料号	机架高度	高度	深度	包装数量	颜色	颜色代码
26230-074	20U	945mm	500mm	2	浅灰色	RAL 7035
26230-075	25U	1167mm	500mm	2	浅灰色	RAL 7035
26230-076	34U	1567mm	500mm	2	浅灰色	RAL 7035
26230-077	38U	1745mm	500mm	2	浅灰色	RAL 7035
26230-078	43U	1967mm	500mm	2	浅灰色	RAL 7035
26230-079	47U	2145mm	500mm	2	浅灰色	RAL 7035
26230-113	12U	531mm	900mm	2	浅灰色	RAL 7035
26230-114	12U	531mm	1000mm	2	浅灰色	RAL 7035
26230-115	16U	709mm	900mm	2	浅灰色	RAL 7035
26230-116	16U	709mm	1000mm	2	浅灰色	RAL 7035
26230-117	20U	887mm	900mm	2	浅灰色	RAL 7035
26230-118	20U	887mm	1000mm	2	浅灰色	RAL 7035
26230-119	25U	1109mm	900mm	2	浅灰色	RAL 7035
26230-120	6U	357mm	600mm	2	浅灰色	RAL 7035
26230-121	9U	490mm	600mm	2	浅灰色	RAL 7035
26230-122	12U	589mm	600mm	2	浅灰色	RAL 7035
26230-123	16U	709mm	600mm	2	浅灰色	RAL 7035

物料号	机架高度	高度	深度	包装数量	颜色	颜色代码
26230-124	20U	945mm	600mm	2	浅灰色	RAL 7035
26230-125	25U	1167mm	600mm	2	浅灰色	RAL 7035
26230-126	34U	1567mm	600mm	2	浅灰色	RAL 7035
26230-127	38U	1745mm	600mm	2	浅灰色	RAL 7035
26230-128	43U	1967mm	600mm	2	浅灰色	RAL 7035
26230-129	47U	2145mm	600mm	2	浅灰色	RAL 7035
26230-130	25U	1109mm	1000mm	2	浅灰色	RAL 7035
26230-131	34U	1509mm	900mm	2	浅灰色	RAL 7035
26230-132	34U	1509mm	1000mm	2	浅灰色	RAL 7035
26230-133	38U	1687mm	900mm	2	浅灰色	RAL 7035
26230-134	38U	1687mm	1000mm	2	浅灰色	RAL 7035
26230-135	43U	1909mm	900mm	2	浅灰色	RAL 7035

Table 2/2				
物料号	完成	类型	认证	快速发货
26230-173	粉末涂层	侧面板	RoHS	No
26230-136	粉末涂层	侧面板	RoHS	No
26230-137	粉末涂层	侧面板	RoHS	No

物料号	完成	类型	认证	快速发货
26230-138	粉末涂层	侧面板	RoHS	No
26230-172	粉末涂层	侧面板	RoHS	No
26230-174	粉末涂层	侧面板	RoHS	No
26230-175	粉末涂层	侧面板	RoHS	No
26230-176	粉末涂层	侧面板	RoHS	No
26230-177	粉末涂层	侧面板	RoHS	No
26230-178	粉末涂层	侧面板	RoHS	No
26230-179	粉末涂层	侧面板	RoHS	No
25230-160	粉末涂层	侧面板		No
25230-161	粉末涂层	侧面板		No
25230-162	粉末涂层	侧面板		No
25230-163	粉末涂层	侧面板		No
25230-164	粉末涂层	侧面板		No
26230-160	粉末涂层	侧面板		No
26230-161	粉末涂层	侧面板		No
26230-162	粉末涂层	侧面板		No
26230-163	粉末涂层	侧面板		No

物料号	完成	类型	认证	快速发货
26230-164	粉末涂层	侧面板		No
25230-070	粉末涂层	侧面板	RoHS	No
25230-071	粉末涂层	侧面板	RoHS	No
25230-072	粉末涂层	侧面板	RoHS	No
25230-073	粉末涂层	侧面板	RoHS	No
25230-074	粉末涂层	侧面板	RoHS	No
25230-075	粉末涂层	侧面板	RoHS	No
25230-076	粉末涂层	侧面板	RoHS	No
25230-077	粉末涂层	侧面板	RoHS	No
25230-078	粉末涂层	侧面板	RoHS	No
25230-079	粉末涂层	侧面板	RoHS	No
25230-113	粉末涂层	侧面板	RoHS	No
25230-114	粉末涂层	侧面板	RoHS	No
25230-115	粉末涂层	侧面板	RoHS	No
25230-116	粉末涂层	侧面板	RoHS	No
25230-117	粉末涂层	侧面板	RoHS	No
25230-118	粉末涂层	侧面板	RoHS	No

物料号	完成	类型	认证	快速发货
25230-119	粉末涂层	侧面板	RoHS	No
25230-120	粉末涂层	侧面板	RoHS	No
25230-121	粉末涂层	侧面板	RoHS	No
25230-122	粉末涂层	侧面板	RoHS	No
25230-123	粉末涂层	侧面板	RoHS	No
25230-124	粉末涂层	侧面板	RoHS	No
25230-125	粉末涂层	侧面板	RoHS	No
25230-126	粉末涂层	侧面板	RoHS	No
25230-127	粉末涂层	侧面板	RoHS	No
25230-128	粉末涂层	侧面板	RoHS	No
25230-129	粉末涂层	侧面板	RoHS	No
25230-130	粉末涂层	侧面板	RoHS	No
25230-131	粉末涂层	侧面板	RoHS	No
25230-132	粉末涂层	侧面板	RoHS	No
25230-133	粉末涂层	侧面板	RoHS	No
25230-134	粉末涂层	侧面板	RoHS	No
25230-135	粉末涂层	侧面板	RoHS	No

物料号	完成	类型	认证	快速发货
25230-136	粉末涂层	侧面板	RoHS	No
25230-137	粉末涂层	侧面板	RoHS	No
25230-138	粉末涂层	侧面板	RoHS	No
25230-172	粉末涂层	侧面板	RoHS	No
25230-173	粉末涂层	侧面板	RoHS	No
25230-174	粉末涂层	侧面板	RoHS	No
25230-175	粉末涂层	侧面板	RoHS	No
25230-176	粉末涂层	侧面板	RoHS	No
25230-177	粉末涂层	侧面板	RoHS	No
25230-178	粉末涂层	侧面板	RoHS	No
25230-179	粉末涂层	侧面板	RoHS	No
26230-070	粉末涂层	侧面板	RoHS	No
26230-071	粉末涂层	侧面板	RoHS	No
26230-072	粉末涂层	侧面板	RoHS	No
26230-073	粉末涂层	侧面板	RoHS	No
26230-074	粉末涂层	侧面板	RoHS	No
26230-075	粉末涂层	侧面板	RoHS	No

物料号	完成	类型	认证	快速发货
26230-076	粉末涂层	侧面板	RoHS	No
26230-077	粉末涂层	侧面板	RoHS	No
26230-078	粉末涂层	侧面板	RoHS	No
26230-079	粉末涂层	侧面板	RoHS	No
26230-113	粉末涂层	侧面板	RoHS	No
26230-114	粉末涂层	侧面板	RoHS	No
26230-115	粉末涂层	侧面板	RoHS	No
26230-116	粉末涂层	侧面板	RoHS	No
26230-117	粉末涂层	侧面板	RoHS	No
26230-118	粉末涂层	侧面板	RoHS	No
26230-119	粉末涂层	侧面板	RoHS	No
26230-120	粉末涂层	侧面板	RoHS	No
26230-121	粉末涂层	侧面板	RoHS	No
26230-122	粉末涂层	侧面板	RoHS	No
26230-123	粉末涂层	侧面板	RoHS	No
26230-124	粉末涂层	侧面板	RoHS	No
26230-125	粉末涂层	侧面板	RoHS	No

物料号	完成	类型	认证	快速发货
26230-126	粉末涂层	侧面板	RoHS	No
26230-127	粉末涂层	侧面板	RoHS	No
26230-128	粉末涂层	侧面板	RoHS	No
26230-129	粉末涂层	侧面板	RoHS	No
26230-130	粉末涂层	侧面板	RoHS	No
26230-131	粉末涂层	侧面板	RoHS	No
26230-132	粉末涂层	侧面板	RoHS	No
26230-133	粉末涂层	侧面板	RoHS	No
26230-134	粉末涂层	侧面板	RoHS	No
26230-135	粉末涂层	侧面板	RoHS	No

其他产品详情

或者使用侧面板锁装配四分之一转舌锁。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE