


# Plug-In Unit Kit for FMC, 镀铬, 把手带屏蔽（织物）

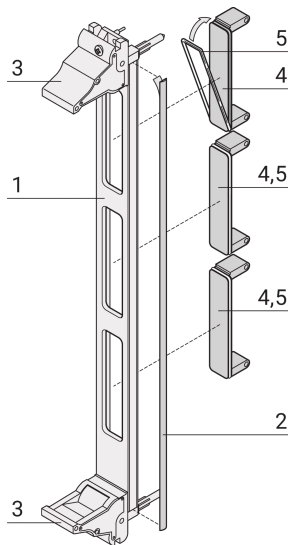

FMC 面板符合 Vita 57.1 规范。覆盖整个前面板上的开孔。

## 认证



## 功能

符合 Vita 57.1 技术参数

适用于单个 69.0 x 76.5 mm 模块或两个 139.0 x 76.5 mm 模块

带有 IEL 把手的铝型材面板

## 技术参数

|       |          |
|-------|----------|
| 机架宽度: | 4HP      |
| 材料:   | 铝        |
| 完成:   | 阳极氧化; 钝化 |

产品类型: 前面板  
类型: 带把手的前面板 (PIU)  
EMC 屏蔽: 是

| Table 1/2 |      |      |      |        |          |        |
|-----------|------|------|------|--------|----------|--------|
| 物料号       | 机架高度 | 包装数量 | 手柄类型 | 安装     | EMC 垫片类型 | 正面表面处理 |
| 20836-253 | 3U   | 1    | IEL  | 正面螺钉安装 | 织物       | 阳极氧化   |
| 20836-254 | 6U   | 1    | IEL  | 正面螺钉安装 | 织物       | 阳极氧化   |

| Table 2/2 |        |      |                          |         |      |      |
|-----------|--------|------|--------------------------|---------|------|------|
| 物料号       | 反面表面处理 | 边缘处理 | 符合                       | 高度      | 宽度   | 快速发货 |
| 20836-253 | 导电     | 否    | FMC<br>夹层板, Vita<br>57.1 | 128.4mm | 20mm | No   |
| 20836-254 | 导电     | 否    | FMC<br>夹层板, Vita<br>57.1 | 261.8mm | 20mm | No   |

**警告**

请勿根据此文档的信息对产品进行任何修改。如需对产品进行任何修改，请咨询 nVent 技术支持团队。如需获取说明书，请向您的 nVent 销售代表索取。

| North America                                                          | Europe                                                                                                                                                                                              | Asia                                                                                                                                                                                      | Middle East & India                                                                                                                                                     |
|------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| All locations<br>+1.763.422.2661<br>Chat with us:<br>nvent.com/schroff | Straubenhardt, Germany<br>+49.7082.794.0<br>Betschdorf, France<br>+33.3.88.90.64.90<br>Warsaw, Poland<br>+48.22.209.98.35<br>Assago, Italy<br>+39.02.932.7141<br>Chat with us:<br>nvent.com/schroff | Shanghai, China<br>+86.21.2412.6943<br>Qingdao, China<br>+86.532.8771.6101<br>Singapore<br>+65.6768.5800<br>Shin-Yokohama, Japan<br>+81.45.476.0271<br>Chat with us:<br>nvent.com/schroff | Dubai, United Arab<br>Emirates<br>+971.4.378.1700<br>Bangalore, India<br>+91.80.6715.2001<br>Istanbul, Turkey<br>+90.216.250.7374<br>Chat with us:<br>nvent.com/schroff |



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE