


适用于 类型1 把手的面板套件-U 型材前面板

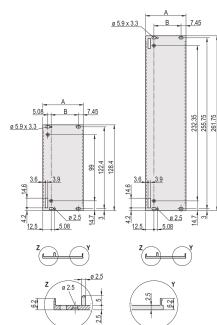

U 型材前面板。可装配 类型1

梯形拉拔式把手。前面板可以用泡棉屏蔽条进行屏蔽。

认证



功能

铝制型材, 正面阳极氧化, 背面导电

前面板, U 型, 屏蔽型

定位销压入, 不锈钢

技术参数

材料:	铝
完成:	阳极氧化; 钝化
附件类型:	前面板
产品类型:	前面板
类型:	带把手的前面板 (PIU)
EMC 屏蔽:	无 (可改装)

Table 1/3

物料号	机架高度	机架宽度	包装数量	手柄类型	安装	垫片类型
-----	------	------	------	------	----	------

30848-461	3U	4HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC
30848-463	3U	6HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC
30848-465	3U	8HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC
30848-468	6U	4HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC
30848-466	3U	10HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC
30848-467	3U	12HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC
30848-470	6U	6HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC
30848-472	6U	8HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC
30848-473	6U	10HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC
30848-474	6U	12HP	1	梯形, 类型 1	正面螺钉安装	织物 EMC

Table 2/3						
物料号	正面表面处理	反面表面处理	边缘处理	符合	深度 (D)	高度 (H)
30848-461	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm
30848-463	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm
30848-465	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm
30848-468	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm

物料号	正面表面处理	反面表面处理	边缘处理	符合	深度 (D)	高度 (H)
30848-466	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm
30848-467	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm
30848-470	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm
30848-472	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm
30848-473	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm
30848-474	阳极氧化	导电	否	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm

Table 3/3

物料号	宽度 (W)	快速发货
30848-461	20mm	No
30848-463	30.1mm	No
30848-465	40.3mm	No
30848-468	20mm	No
30848-466	50.5mm	No
30848-467	60.6mm	No
30848-470	30.1mm	No

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE