


PropacPRO EMC 后面板, 全宽

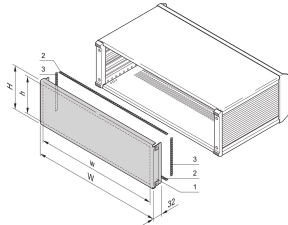

适用于 PropacPRO 机箱的全宽 EMC 后面板，安装在机箱框架上。没有通风孔。通过 EMC 泡棉屏蔽条实现屏蔽。

认证



功能

铝板, 1.5 mm, 带用于接地的紧固件

安装在仪器箱上（左，右两侧固定）

无通风孔

技术参数

材料: 铝
完成: 阳极氧化; 钝化
搭配: 仪器箱
产品系列: PropacPRO
类型: 背板
产品类型: 侧面板

Table 1/1

物料号	机架高度	机架宽度	包装数量	快速发货
-----	------	------	------	------

24576-244	2U	42HP	1	No
24576-247	3U	28HP	1	No
24576-248	3U	42HP	1	No
24576-245	2U	63HP	1	No
24576-252	4U	42HP	1	No
24576-249	3U	63HP	1	No
24576-250	3U	84HP	1	No
24576-253	4U	63HP	1	No
24576-254	4U	84HP	1	No
24576-258	6U	84HP	1	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE