


PropacPRO 前面板, 全宽, 非屏蔽型

适用于 PropacPRO 机箱的全宽前面板，可安装在机箱框架上。

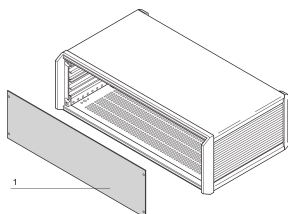

认证



功能

铝面板, 2.0 mm (84 HP 2.5 mm)

技术参数

材料: 铝
完成: 阳极氧化
附件类型: 前面板
产品类型: 前面板

Table 1/2

物料号	机架高度	机架宽度	包装数量	正面表面处理	反面表面处理	边缘处理
20850-128	2U	42HP	1	阳极氧化	阳极氧化	否
20850-134	3U	28HP	1	阳极氧化	阳极氧化	否
20850-129	2U	63HP	1	阳极氧化	阳极氧化	否

物料号	机架高度	机架宽度	包装数量	正面表面处理	反面表面处理	边缘处理
20850-135	3U	42HP	1	阳极氧化	阳极氧化	否
20850-142	4U	42HP	1	阳极氧化	阳极氧化	否
20850-136	3U	63HP	1	阳极氧化	阳极氧化	否
20850-130	2U	84HP	1	阳极氧化	阳极氧化	否
20850-143	4U	63HP	1	阳极氧化	阳极氧化	否
20850-137	3U	84HP	1	阳极氧化	阳极氧化	否
20850-144	4U	84HP	1	阳极氧化	阳极氧化	否
20850-158	6U	84HP	1	阳极氧化	导电	否

Table 2/2				
物料号	深度	高度	宽度	快速发货
20850-128	2mm	84mm	238.7mm	No
20850-134	2mm	128.5mm	167.6mm	No
20850-129	2mm	84mm	345.4mm	No
20850-135	2mm	128.5mm	238.7mm	No
20850-142	2mm	172.9mm	238.7mm	No
20850-136	2mm	128.5mm	345.4mm	No
20850-130	2.5mm	84mm	452mm	No

物料号	深度	高度	宽度	快速发货
20850-143	2mm	172.9mm	345.4mm	No
20850-137	2.5mm	128.5mm	452mm	No
20850-144	2.5mm	172.9mm	452mm	No
20850-158	2.5mm	261.8mm	452mm	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE