


PropacPRO 后面板, 全宽, 非屏蔽型

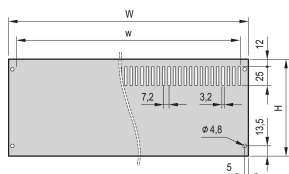

适用于 PropacPRO

机箱的全宽后面板，可安装在机箱框架上。可选择带或不带通风槽

。

认证



功能

铝板, 2.0 mm (84 HP 2.5 mm)

使用支架安装在机箱上（左侧和右侧）

技术参数

材料: 铝
完成: 阳极氧化
搭配: 仪器箱
产品系列: PropacPRO
类型: 背板
产品类型: 侧面板

Table 1/1

物料号	机架高度	机架宽度	设计特征	包装数量	快速发货
24576-044	2U	42HP	非穿孔	1	No
24576-144	2U	42HP	穿孔	1	No

物料号	机架高度	机架宽度	设计特征	包装数量	快速发货
24576-045	2U	63HP	非穿孔	1	No
24576-145	2U	63HP	穿孔	1	No
24576-047	3U	28HP	非穿孔	1	No
24576-147	3U	28HP	穿孔	1	No
24576-048	3U	42HP	非穿孔	1	No
24576-148	3U	42HP	穿孔	1	No
24576-049	3U	63HP	非穿孔	1	No
24576-149	3U	63HP	穿孔	1	No
24576-050	3U	84HP	非穿孔	1	No
24576-150	3U	84HP	穿孔	1	No
24576-052	4U	42HP	非穿孔	1	No
24576-152	4U	42HP	穿孔	1	No
24576-053	4U	63HP	非穿孔	1	No
24576-153	4U	63HP	穿孔	1	No
24576-054	4U	84HP	非穿孔	1	No
24576-154	4U	84HP	穿孔	1	No
24576-058	6U	84HP	非穿孔	1	No

物料号	机架高度	机架宽度	设计特征	包装数量	快速发货
24576-158	6U	84HP	穿孔	1	No
24576-046	2U	84HP	非穿孔	1	No
24576-146	2U	84HP	穿孔	1	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE