


速卸锁扣

1/4 旋转锁，支持预定义的锁定位置。

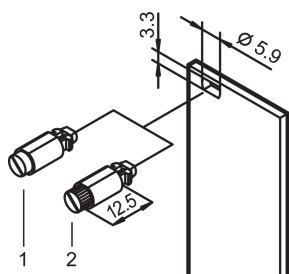

认证



功能

1/4 旋转锁，支持预定义的锁定位置

根据插槽位置识别锁定位置

抗振动，抗摇晃

数量 100 件

技术参数

搭配: 前面板
产品类型: 硬件套件
完成: 镀镍
材料: 钢; 锌合金; 热塑性

Table 1/2

物料号	颜色	包装数量	颜色代码	深度	高度	宽度
21101-848	墨黑色	100	RAL 9005	16.7mm	6mm	7mm

物料号	颜色	包装数量	颜色代码	深度	高度	宽度
21101-847	卵石灰	100	RAL 7032	16.7mm	6mm	7mm
21101-850	墨黑色	100	RAL 9005	20.6mm	6mm	7mm
21101-849	卵石灰	100	RAL 7032	20.6mm	6mm	7mm

Table 2/2		
物料号	紧固件类型	快速发货
21101-848	开槽头型	No
21101-847	开槽头型	No
21101-850	滚花, 开槽头型	No
21101-849	滚花, 开槽头型	No

其他产品详情

速卸锁扣：无需螺纹插件即可安装。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE