


RatiopacPRO AIR 离心风扇单元

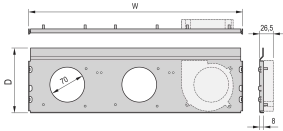

适用于 RatiopacPRO AIR 的可轻松安装的离心风扇，每风扇的风量 $36 \text{ m}^3/\text{h}$ （自由送风量）。可提供 4 种宽度和 2 种深度版本，最多配备 3 个风扇。

认证



功能

滚珠轴承离心风扇

每风扇的风量 $36 \text{ m}^3/\text{h}$ （自由送风量）

适合 RatiopacPRO Air 机箱（风扇单元仅需 0,5 U 高度）

仅 1/2 U 高度

通过盖板开孔排气

背面安装空间无限制

无需对机箱进行机械改造

轻松安装

技术参数

材料:	铝
搭配:	仪器箱
产品类型:	风扇
类型:	离心风扇
产品系列:	RatiopacPRO AIR

Table 1/1						
物料号	机架宽度	直流电压	气流	深度	宽度	快速发货
24572-408	28HP	12V	36m³/h	220mm	146.87mm	No
24572-405	42HP	12V	36m³/h	160mm	218mm	No
24572-409	42HP	12V	36m³/h	220mm	218mm	No
24572-406	63HP	12V	36m³/h	160mm	324.67mm	No
24572-410	63HP	12V	36m³/h	220mm	324.67mm	No
24572-407	84HP	12V	36m³/h	160mm	431.35mm	No
24572-411	84HP	12V	36m³/h	220mm	431.35mm	No
24572-404	28HP	12V	36m³/h	160mm	146.87mm	No

警告

应仔细阅读 nVent 的产品说明书并培训材料内容并使用 nVent 的产品。可访问 <https://www.schroff.com> 获取说明书。或者向你的 nVent

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	Emirates
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE