


RatiopacPRO EMC 前面板, 开槽, 屏蔽型

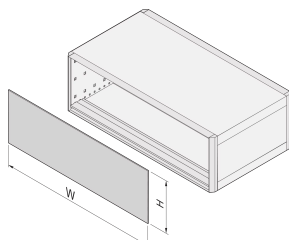

EMC

前面板可以插入具有抬高设计的特殊水平轨道中。无需螺钉即可固定。此设计可方便用户使用前面板贴膜。

认证



功能

无螺钉固定

特殊的水平轨道覆盖前面板（顶部和底部）的边缘，防止前面板弯曲

技术参数

材料: 铝
完成: 阳极氧化; 钝化
附件类型: 前面板
产品类型: 前面板

Table 1/2

物料号	机架高度	机架宽度	包装数量	正面表面处理	反面表面处理	边缘处理
24572-603	3U	28HP	1	阳极氧化	导电	否
24572-604	3U	42HP	1	阳极氧化	导电	否

物料号	机架高度	机架宽度	包装数量	正面表面处理	反面表面处理	边缘处理
24572-605	3U	63HP	1	阳极氧化	导电	否
24572-606	3U	84HP	1	阳极氧化	导电	否
24572-607	4U	28HP	1	阳极氧化	导电	否
24572-608	4U	42HP	1	阳极氧化	导电	否
24572-609	4U	63HP	1	阳极氧化	导电	否
24572-610	4U	84HP	1	阳极氧化	导电	否
24572-599	2U	28HP	1	阳极氧化	导电	否
24572-600	2U	42HP	1	阳极氧化	导电	否
24572-601	2U	63HP	1	阳极氧化	导电	否
24572-602	2U	84HP	1	阳极氧化	导电	否

Table 2/2				
物料号	深度	高度	宽度	快速发货
24572-603	2.5mm	128.4mm	141.9mm	No
24572-604	2.5mm	128.4mm	213.2mm	No
24572-605	2.5mm	128.4mm	319.7mm	No
24572-606	2.5mm	128.4mm	426.4mm	No
24572-607	2.5mm	172.9mm	141.9mm	No

物料号	深度	高度	宽度	快速发货
24572-608	2.5mm	172.9mm	213.2mm	No
24572-609	2.5mm	172.9mm	319.7mm	No
24572-610	2.5mm	172.9mm	426.4mm	No
24572-599	2.5mm	84mm	141.9mm	No
24572-600	2.5mm	84mm	213.2mm	No
24572-601	2.5mm	84mm	319.7mm	No
24572-602	2.5mm	84mm	426.4mm	No

其他产品详情

要获得屏蔽型机箱，必须安装所有 EMC 密封件（前面板/后面板 - 侧板）水平轨道；侧板 - 盖板；前面板/后面板 - ；水平轨道 - 水平轨道）。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE