


# RatiopacPro 旋转把手装配套件

如果要安装折叠式把手，必须使用装配套件。应更换标准侧盖。

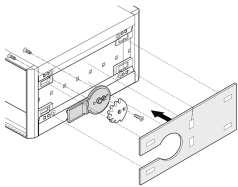

## 认证



## 功能

铝侧面板，粉末涂层，RAL 9006, 转接卡和装配材料。

## 技术参数

产品类型: 装配组件  
 搭配: 仪器箱  
 产品系列: RatiopacPRO; RatiopacPRO AIR  
 类型: 翻转式把手套装

Table 1/2

| 物料号       | 机架高度 | 机架宽度 | 深度    | 包装数量 | 完成   | 材料 |
|-----------|------|------|-------|------|------|----|
| 24571-352 | 3U   | 42HP | 255mm | 2    | 粉末涂层 | 铝  |
| 24571-353 | 3U   | 42HP | 315mm | 2    | 粉末涂层 | 铝  |

| 物料号       | 机架高度 | 机架宽度 | 深度    | 包装数量 | 完成   | 材料 |
|-----------|------|------|-------|------|------|----|
| 24571-354 | 3U   | 42HP | 375mm | 2    | 粉末涂层 | 铝  |
| 24571-359 | 4U   | 42HP | 255mm | 2    | 粉末涂层 | 铝  |
| 24571-360 | 4U   | 42HP | 315mm | 2    | 粉末涂层 | 铝  |
| 24571-355 | 3U   | 42HP | 435mm | 2    | 粉末涂层 | 铝  |
| 24571-356 | 3U   | 42HP | 495mm | 2    | 粉末涂层 | 铝  |
| 24571-361 | 4U   | 42HP | 375mm | 2    | 粉末涂层 | 铝  |
| 24571-362 | 4U   | 42HP | 435mm | 2    | 粉末涂层 | 铝  |
| 24571-363 | 4U   | 42HP | 495mm | 2    | 粉末涂层 | 铝  |

| Table 2/2 |      |
|-----------|------|
| 物料号       | 快速发货 |
| 24571-352 | No   |
| 24571-353 | No   |
| 24571-354 | No   |
| 24571-359 | No   |
| 24571-360 | No   |
| 24571-355 | No   |
| 24571-356 | No   |

| 物料号       | 快速发货 |
|-----------|------|
| 24571-361 | No   |
| 24571-362 | No   |
| 24571-363 | No   |

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

| North America                                                                                                 | Europe                                                                                                                                                                                                                                     | Asia                                                                                                                                                                                                                             | Middle East & India                                                                                                                                                                                         |
|---------------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| All locations<br>+1.763.422.2661<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> | Straubenhardt, Germany<br>+49.7082.794.0<br>Betschdorf, France<br>+33.3.88.90.64.90<br>Warsaw, Poland<br>+48.22.209.98.35<br>Assago, Italy<br>+39.02.932.7141<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> | Shanghai, China<br>+86.21.2412.6943<br>Qingdao, China<br>+86.532.8771.6101<br>Singapore<br>+65.6768.5800<br>Shin-Yokohama, Japan<br>+81.45.476.0271<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> | Dubai, United Arab Emirates<br>+971.4.378.1700<br>Bangalore, India<br>+91.80.6715.2001<br>Istanbul, Turkey<br>+90.216.250.7374<br>Chat with us:<br><a href="http://nvent.com/schroff">nvent.com/schroff</a> |



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE