


适用于 RatiopacPRO/PropacPRO 的后面板, 通风孔, 非屏蔽型

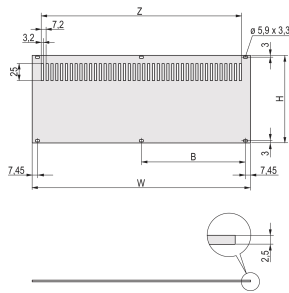

铝制 2.5 mm 网孔后面板为屏蔽型面板。背面具有导电性。

认证



功能

背面板, 铝, 2.5 mm, 前部: 阳极氧化, 后部: 导电; 非屏蔽

可以安装在水平轨道上

可以安装在水平轨道上

技术参数

材料:	铝
完成:	阳极氧化; 钝化
搭配:	仪器箱
产品系列:	RatiopacPRO; RatiopacPRO AIR
类型:	背板
产品类型:	侧面板

Table 1/1

物料号	机架高度	机架宽度	包装数量	高度	宽度	快速发货
30849-014	2U	42HP	1	67.9mm	213mm	No
30849-016	2U	84HP	1	67.9mm	426.4mm	No
30849-008	3U	28HP	1	112.35mm	141.9mm	No
30849-021	3U	42HP	1	112.35mm	213mm	No
30849-022	3U	63HP	1	112.35mm	319.7mm	No
30849-023	3U	84HP	1	112.35mm	426.4mm	No
30849-028	4U	42HP	1	156.8mm	213mm	No
30849-029	4U	63HP	1	156.8mm	319.7mm	No
30849-030	4U	84HP	1	156.8mm	426.4mm	No
30849-037	6U	84HP	1	245.7mm	426.4mm	No
30849-036	6U	63HP	1	245.7mm	319.7mm	No
30849-015	2U	63HP	1	67.9mm	319.7mm	No
30849-009	4U	28HP	1	156.8mm	141.9mm	No
30849-010	6U	28HP	1	245.7mm	141.9mm	No
30849-035	6U	42HP	1	245.7mm	213mm	No
30849-007	2U	28HP	1	67.9mm	141.9mm	No

物料号	机架高度	机架宽度	包装数量	高度	宽度	快速发货
30849-011	5U	28HP	1	220mm	215mm	No
30849-171	5U	42HP	1	220mm	215mm	No
30849-172	5U	63HP	1	220mm	215mm	No
30849-173		84HP	1	220mm	215mm	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE