


适用于 M2.5 的套管

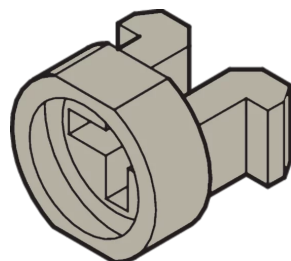

紧固前面板时，螺钉套可用于引导固定螺钉。

认证



功能

紧固前面板时，螺钉套可用于螺钉安装导向定位

螺钉套装在前面板上的长圆孔中

技术参数

搭配：前面板

产品类型：套管

Table 1/2

物料号	材料	完成	颜色	包装数量	颜色代码	深度 (D)
21100-659	黄铜	镀镍		10		
21100-661	不锈钢			10		
21100-662	不锈钢			100		4.4mm


物料号	材料	完成	颜色	包装数量	颜色代码	深度 (D)
21100-660	黄铜	镀镍		100		4.4mm
21100-886	黄铜	有机面涂层		100		4.4mm
21100-464	聚酰胺 6		卵石灰	100	RAL 7032	6.9mm
21100-591	聚酰胺 6		墨黑色	100	RAL 9005	6.9mm
21100-885	黄铜			10		

Table 2/2				
物料号	高度 (H)	宽度 (W)	可燃性等级	快速发货
21100-659				No
21100-661				No
21100-662	6mm	8mm		No
21100-660	6mm	8mm		No
21100-886	6mm	8mm		No
21100-464	6mm	6.8mm	UL® 94V-2	No
21100-591	6mm	6.8mm	UL® 94V-2	No
21100-885				No

其他产品详情

金属螺钉套， 必须压入面板中

所有套管都可以用于 >2 HP 的前面板。

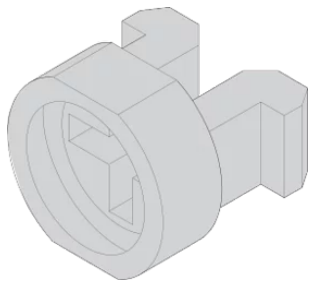

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE