


静态梯形塑料把手, 黑色

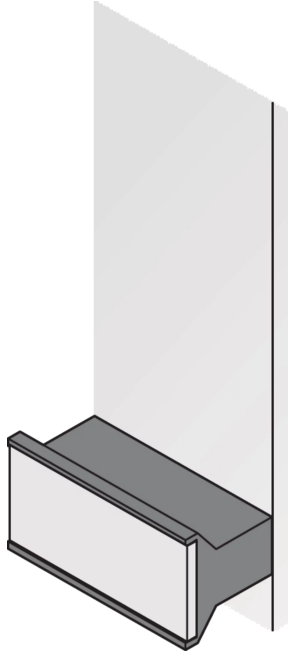

梯形黑色静态塑料把手可以安装到前面板上，用于拔出 PCB。

认证



功能

带独立识别板, Al 1.5 mm

把手, PC, UL 94 V-0

技术参数

搭配:	前面板
产品类型:	手柄
材料:	聚碳酸酯
类型:	静态

Table 1/2

物料号	机架宽度	包装数量	手柄类型	可燃性等级	颜色	符合
20808-082	7HP	1	梯形, 静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-088	21HP	1	梯形, 静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-089	28HP	1	梯形, 静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-090	40HP	1	梯形, 静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-091	42HP	1	梯形, 静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-080	5HP	1	梯形, 静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-081	6HP	1	梯形, 静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-083	8HP	1	梯形, 静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-084	9HP	1	梯形, 静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

物料号	机架宽度	包装数量	手柄类型	可燃性等级	颜色	符合
20808-085	10HP	1	梯形，静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-086	12HP	1	梯形，静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-087	14HP	1	梯形，静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-396	3HP	1	梯形，静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-397	4HP	1	梯形，静态	UL® 94V-0	黑色	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

Table 2/2		
物料号	宽度 (W)	快速发货
20808-082	34.1mm	No
20808-088	105.2mm	No
20808-089	140.8mm	No
20808-090	201.8mm	No
20808-091	212mm	No
20808-080	24mm	No


物料号	宽度 (W)	快速发货
20808-081	29mm	No
20808-083	39.2mm	No
20808-084	44.3mm	No
20808-085	49.4mm	No
20808-086	59.6mm	No
20808-087	69.7mm	No
20809-396	13.8mm	No
20809-397	18.9mm	No

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

不能与固定夹一起使用 (21101-239)。

图

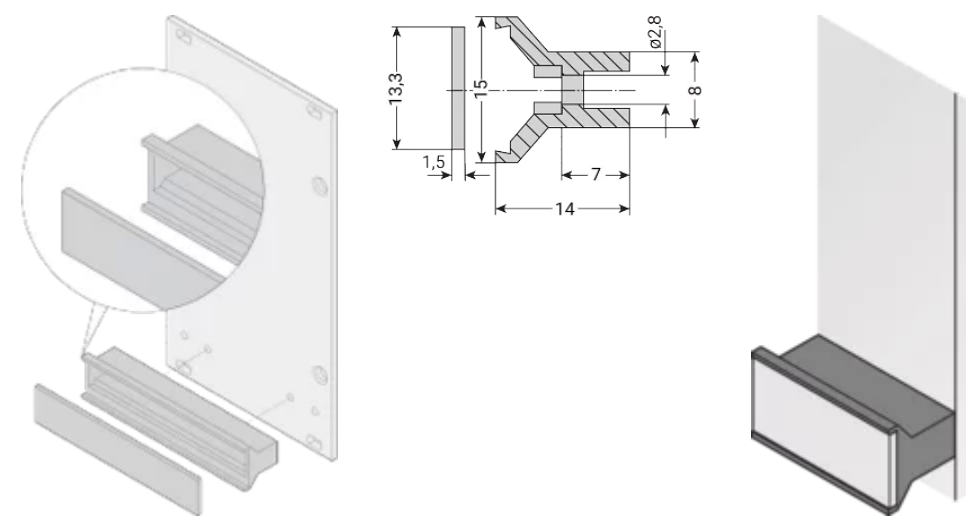

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE