


Varistar CP Mobile Base/Plinth

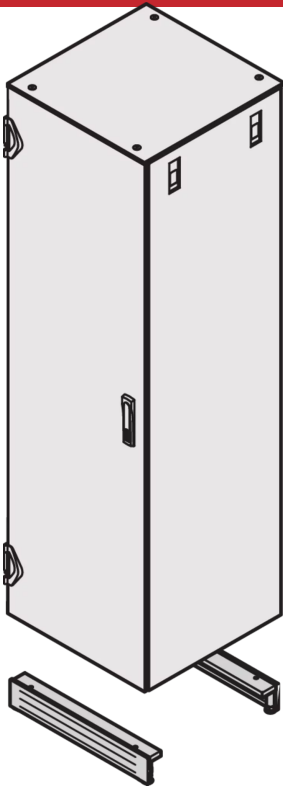

移动基座/底座，使机柜具有移动性。

功能

盖, 碳钢, 1.5 mm

脚轮承载能力 400 千克, 可调节支脚 1600 千克

支撑件, 碳钢, 3 mm

颜色 RAL 7021

底座高度 H = 103 mm, 支脚调节范围从 126 至 134 mm

技术参数

产品类型: 机柜/机架底座

材料: 钢

Table 1/2

物料号	宽度	深度	包装数量	颜色	颜色代码	完成
21630-664	800mm	1000mm	1	暗灰色	RAL 7021	粉末涂层
21630-655	600mm	600mm	1	暗灰色	RAL 7021	粉末涂层
21630-663	800mm	900mm	1	暗灰色	RAL 7021	粉末涂层
21630-662	800mm	800mm	1	暗灰色	RAL 7021	粉末涂层
21630-661	800mm	600mm	1			粉末涂层
21630-658	600mm	1000mm	1	暗灰色	RAL 7021	粉末涂层
21630-657	600mm	900mm	1	暗灰色	RAL 7021	粉末涂层
21630-656	600mm	800mm	1	暗灰色	RAL 7021	粉末涂层

Table 2/2

物料号	类型	搭配	快速发货
21630-664	底座，移动式	Varistar CP	No
21630-655	底座，移动式	Varistar CP	No
21630-663	底座，移动式	Varistar CP	No
21630-662	底座，移动式	Varistar CP	No
21630-661	底座，移动式	Varistar CP	No
21630-658	底座，移动式	Varistar CP	No
21630-657	底座，移动式	Varistar CP	No

物料号	类型	搭配	快速发货
21630-656	底座，移动式	Varistar CP	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE