


Varistar CP Seismic Base Plate, 多段复合式

多件底板从内部组装。

请单独订购接地、盖板、毛刷条或过滤垫。

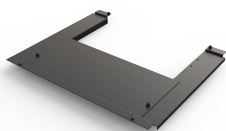

功能

覆盖底部开口

多件式底板在后部打开（向后打开 200 毫米深），无后开口，机柜深度为 300 mm）

技术参数

产品类型： 机柜/机架底座

材料： 钢

Table 1/2

物料号	宽度	深度	包装数量	颜色	颜色代码	符合
20630-293	600mm	600mm	1	暗灰色	RAL 7021	IEC 61587-1, IEC 61587-2
20630-294	600mm	800mm	1	暗灰色	RAL 7021	IEC 61587-1, IEC 61587-2
20630-295	600mm	1000mm	1	暗灰色	RAL 7021	IEC 61587-1, IEC 61587-2
20630-296	600mm	1200mm	1	暗灰色	RAL 7021	IEC 61587-1, IEC 61587-2
20630-297	800mm	600mm	1	暗灰色	RAL 7021	IEC 61587-1, IEC 61587-2

物料号	宽度	深度	包装数量	颜色	颜色代码	符合
20630-298	800mm	800mm	1	暗灰色	RAL 7021	IEC 61587-1, IEC 61587-2
20630-299	800mm	1000mm	1	暗灰色	RAL 7021	IEC 61587-1, IEC 61587-2
20630-300	800mm	1200mm	1	暗灰色	RAL 7021	IEC 61587-1, IEC 61587-2

Table 2/2				
物料号	完成	类型	搭配	快速发货
20630-293	粉末涂层	底板，平板	Varistar CP	No
20630-294	粉末涂层	底板，平板	Varistar CP	No
20630-295	粉末涂层	底板，平板	Varistar CP	No
20630-296	粉末涂层	底板，平板	Varistar CP	No
20630-297	粉末涂层	底板，平板	Varistar CP	No
20630-298	粉末涂层	底板，平板	Varistar CP	No
20630-299	粉末涂层	底板，平板	Varistar CP	No
20630-300	粉末涂层	底板，平板	Varistar CP	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE