


Varistar CP 钢板门, Glazed With 3-Point Locking, 尺寸缩短型

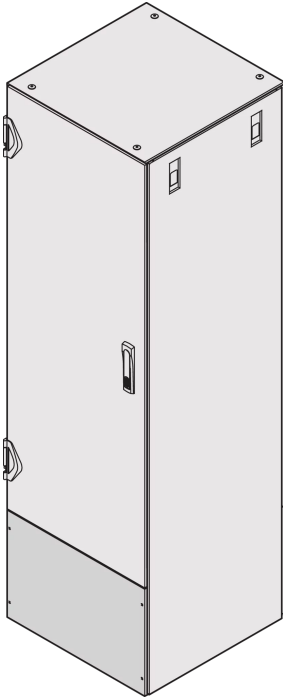

可用于 IP20、IP55 应用的缩短门。

功能

玻璃门

连接板高度 400 mm

技术参数

锁定类型: 3 点锁定

产品类型: 机柜门

防护等级: IP20

材料: 钢

Table 1/2

物料号	机架高度	高度	宽度	包装数量	颜色	颜色代码
-----	------	----	----	------	----	------

21630-346	47U	2200mm	600mm	1	暗灰色	RAL 7021
21630-342	38U	1800mm	600mm	1	暗灰色	RAL 7021
21630-347	47U	2200mm	800mm	1	暗灰色	RAL 7021
21630-345	42U	2000mm	800mm	1	暗灰色	RAL 7021
21630-343	38U	1800mm	800mm	1	暗灰色	RAL 7021
21630-344	42U	2000mm	600mm	1	暗灰色	RAL 7021

Table 2/2		
物料号	完成	快速发货
21630-346	粉末涂层	No
21630-342	粉末涂层	No
21630-347	粉末涂层	No
21630-345	粉末涂层	No
21630-343	粉末涂层	No
21630-344	粉末涂层	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE