


Varistar CP Top Cover With Fan Tray

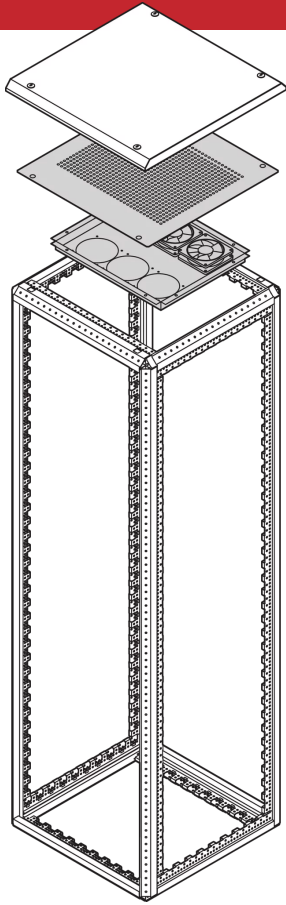

Varistar Fan Top Cover with 3 Fans, expandable to 6 fans.

功能

6 axial fans fitted

Schuko/IEC 60320 C12 plug

6 power saving axial fans fitted

Wide range power input 90-260 VAC

Speed control with 2 T_{box} sensors

Alarm over T_{box} and fan fail (Display panel at front & relay outputs)

Remote control over Modbus RTU or Guardian

技术参数

产品类型: 风扇
材料: 钢

Table 1/3						
物料号	宽度	深度	包装数量	直流电压	气流	噪音等级
21630-777	600mm	600mm	1	24V	171m³/h	42.5dB(A)
21630-778	600mm	800mm	1	24V	171m³/h	42.5dB(A)
21630-783	800mm	600mm	1	24V	171m³/h	42.5dB(A)
21630-784	800mm	800mm	1	24V	171m³/h	42.5dB(A)
21630-785	800mm	900mm	1	24V	171m³/h	42.5dB(A)
21630-786	800mm	1000mm	1	24V	171m³/h	42.5dB(A)
21630-779	600mm	900mm	1	24V	171m³/h	42.5dB(A)
21630-780	600mm	1000mm	1	24V	171m³/h	42.5dB(A)
21630-781	600mm	1100mm	1	24V	171m³/h	42.5dB(A)
21630-782	600mm	1200mm	1	24V	171m³/h	42.5dB(A)
21630-787	800mm	1100mm	1	24V	171m³/h	42.5dB(A)
21630-788	800mm	1200mm	1	24V	171m³/h	42.5dB(A)
21630-790	600mm	600mm	1	24V	171m³/h	42.5dB(A)
21630-791	600mm	800mm	1	24V	171m³/h	42.5dB(A)

物料号	宽度	深度	包装数量	直流电压	气流	噪音等级
21630-792	600mm	900mm	1	24V	171m³/h	42.5dB(A)
21630-793	600mm	1000mm	1	24V	171m³/h	42.5dB(A)
21630-794	600mm	1100mm	1	24V	171m³/h	42.5dB(A)
21630-795	600mm	1200mm	1	24V	171m³/h	42.5dB(A)
21630-796	800mm	600mm	1	24V	171m³/h	42.5dB(A)
21630-797	800mm	800mm	1	24V	171m³/h	42.5dB(A)
21630-798	800mm	900mm	1	24V	171m³/h	42.5dB(A)
21630-799	800mm	1000mm	1	24V	171m³/h	42.5dB(A)
21630-800	800mm	1100mm	1	24V	171m³/h	42.5dB(A)
21630-801	800mm	1200mm	1	24V	171m³/h	42.5dB(A)

Table 2/3						
物料号	最大静压	颜色	颜色代码	符合	完成	防护等级
21630-777	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-778	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-783	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-784	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-785	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20

物料号	最大静压	颜色	颜色代码	符合	完成	防护等级
21630-786	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-779	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-780	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-781	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-782	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	
21630-787	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-788	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-790	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-791	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-792	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-793	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-794	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-795	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-796	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-797	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-798	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-799	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20

物料号	最大静压	颜色	颜色代码	符合	完成	防护等级
21630-800	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20
21630-801	68.1Pa	暗灰色	RAL 7021	IEC 61587-1	粉末涂层	IP20

Table 3/3			
物料号	类型	搭配	快速发货
21630-777	带风扇的顶盖	Varistar CP	No
21630-778	带风扇的顶盖	Varistar CP	No
21630-783	带风扇的顶盖	Varistar CP	No
21630-784	带风扇的顶盖	Varistar CP	No
21630-785	带风扇的顶盖	Varistar CP	No
21630-786	带风扇的顶盖	Varistar CP	No
21630-779	带风扇的顶盖	Varistar CP	No
21630-780	带风扇的顶盖	Varistar CP	No
21630-781	带风扇的顶盖	Varistar CP	No
21630-782	带风扇的顶盖	Varistar CP	No
21630-787	带风扇的顶盖	Varistar CP	No
21630-788	带风扇的顶盖	Varistar CP	No
21630-790	带风扇的顶盖	Varistar CP	No

物料号	类型	搭配	快速发货
21630-791	带风扇的顶盖	Varistar CP	No
21630-792	带风扇的顶盖	Varistar CP	No
21630-793	带风扇的顶盖	Varistar CP	No
21630-794	带风扇的顶盖	Varistar CP	No
21630-795	带风扇的顶盖	Varistar CP	No
21630-796	带风扇的顶盖	Varistar CP	No
21630-797	带风扇的顶盖	Varistar CP	No
21630-798	带风扇的顶盖	Varistar CP	No
21630-799	带风扇的顶盖	Varistar CP	No
21630-800	带风扇的顶盖	Varistar CP	No
21630-801	带风扇的顶盖	Varistar CP	No

其他产品详情

Please purchase the grounding kit separately.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE