


Varistar CP Top Cover Fan

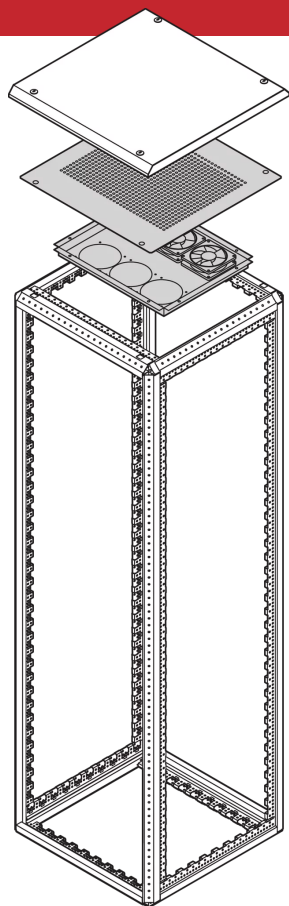

Varistar Fan Top Cover with 3 Fans, expandable to 6 fans.

功能

3 axial fans fitted (maximum: 6 fans)

C14 Socket

技术参数

产品类型: 风扇

材料: 钢

Table 1/2

物料号	宽度	深度	包装数量	颜色	颜色代码	完成
-----	----	----	------	----	------	----

21630-597	600mm	600mm	1	暗灰色	RAL 7021	粉末涂层
21630-598	600mm	800mm	1	暗灰色	RAL 7021	粉末涂层
21630-736	800mm	600mm	1	暗灰色	RAL 7021	粉末涂层
21630-737	800mm	800mm	1	暗灰色	RAL 7021	粉末涂层
21630-738	800mm	900mm	1	暗灰色	RAL 7021	粉末涂层
21630-739	800mm	1000mm	1	暗灰色	RAL 7021	粉末涂层
21630-599	600mm	900mm	1	暗灰色	RAL 7021	粉末涂层
21630-600	600mm	1000mm	1	暗灰色	RAL 7021	粉末涂层
21630-601	600mm	1100mm	1	暗灰色	RAL 7021	粉末涂层
21630-602	600mm	1200mm	1	暗灰色	RAL 7021	粉末涂层
21630-603	600mm	600mm	1	暗灰色	RAL 7021	粉末涂层
21630-604	600mm	800mm	1	暗灰色	RAL 7021	粉末涂层
21630-605	600mm	900mm	1	暗灰色	RAL 7021	粉末涂层
21630-606	600mm	1000mm	1	暗灰色	RAL 7021	粉末涂层
21630-607	600mm	1100mm	1	暗灰色	RAL 7021	粉末涂层
21630-608	600mm	1200mm	1	暗灰色	RAL 7021	粉末涂层
21630-609	800mm	600mm	1	暗灰色	RAL 7021	粉末涂层

21630-610	800mm	800mm	1	暗灰色	RAL 7021	粉末涂层
21630-611	800mm	900mm	1	暗灰色	RAL 7021	粉末涂层
21630-612	800mm	1000mm	1	暗灰色	RAL 7021	粉末涂层
21630-613	800mm	1100mm	1	暗灰色	RAL 7021	粉末涂层
21630-614	800mm	1200mm	1	暗灰色	RAL 7021	粉末涂层
21630-740	800mm	1100mm	1	暗灰色	RAL 7021	粉末涂层
21630-741	800mm	1200mm	1	暗灰色	RAL 7021	粉末涂层

Table 2/2			
物料号	防护等级	搭配	快速发货
21630-597	IP20		No
21630-598	IP20		No
21630-736	IP20		No
21630-737	IP20		No
21630-738	IP20		No
21630-739	IP20		No
21630-599	IP20		No
21630-600	IP20		No
21630-601	IP20		No

物料号	防护等级	搭配	快速发货
21630-602	IP20		No
21630-603		Varistar CP	No
21630-604		Varistar CP	No
21630-605		Varistar CP	No
21630-606		Varistar CP	No
21630-607		Varistar CP	No
21630-608		Varistar CP	No
21630-609		Varistar CP	No
21630-610		Varistar CP	No
21630-611		Varistar CP	No
21630-612		Varistar CP	No
21630-613		Varistar CP	No
21630-614		Varistar CP	No
21630-740	IP20		No
21630-741	IP20		No

其他产品详情

Please purchase the grounding kit, power cable, Thermostat or Speed controller separately.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE