


Varistar Deco 框转接支架

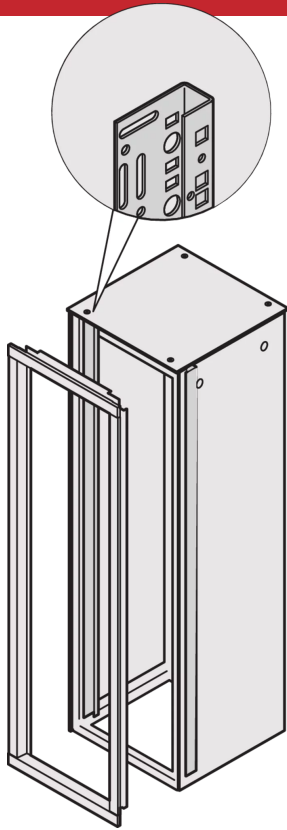

转接支架有助于为带装饰框的 Varistar 机柜装配滑轨和层板。

认证



功能

用于将 L 轨和层板装配在 Varistar 装饰框中

技术参数

产品类型: 支架

材料: 钢

Table 1/2						
物料号	机架高度	高度	包装数量	颜色	颜色代码	完成
23130-220	24U	1200mm	2	暗灰色	RAL 7021	粉末涂层
23130-221	29U	1400mm	2	暗灰色	RAL 7021	粉末涂层
23130-222	33U	1600mm	2	暗灰色	RAL 7021	粉末涂层
23130-223	38U	1800mm	2	暗灰色	RAL 7021	粉末涂层
23130-224	42U	2000mm	2	暗灰色	RAL 7021	粉末涂层
23130-225	47U	2200mm	2	暗灰色	RAL 7021	粉末涂层
23130-230	24U	1200mm	2	浅灰色	RAL 7035	粉末涂层
23130-231	29U	1400mm	2	浅灰色	RAL 7035	粉末涂层
23130-232	33U	1600mm	2	浅灰色	RAL 7035	粉末涂层
23130-233	38U	1800mm	2	浅灰色	RAL 7035	粉末涂层
23130-234	42U	2000mm	2	浅灰色	RAL 7035	粉末涂层
23130-235	47U	2200mm	2	浅灰色	RAL 7035	粉末涂层

Table 2/2				
物料号	类型	宽度	搭配	快速发货
23130-220	支架	600mm	Varistar, Varistar CP	No
23130-221	Deco 装饰框支架	600mm	机柜, Varistar CP	No

物料号	类型	宽度	搭配	快速发货
23130-222	Deco 装饰框支架	600mm	机柜, Varistar CP	No
23130-223	Deco 装饰框支架	600mm	机柜, Varistar CP	No
23130-224	Deco 装饰框支架	600mm	机柜, Varistar CP	No
23130-225	Deco 装饰框支架	600mm	机柜, Varistar CP	No
23130-230	Deco 装饰框支架	600mm	机柜	No
23130-231	Deco 装饰框支架	600mm	机柜	No
23130-232	Deco 装饰框支架	600mm	机柜	No
23130-233	Deco 装饰框支架	600mm	机柜	No
23130-234	Deco 装饰框支架	600mm	机柜	No
23130-235	Deco 装饰框支架	600mm	机柜	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE