


# Varistar 深度支撑

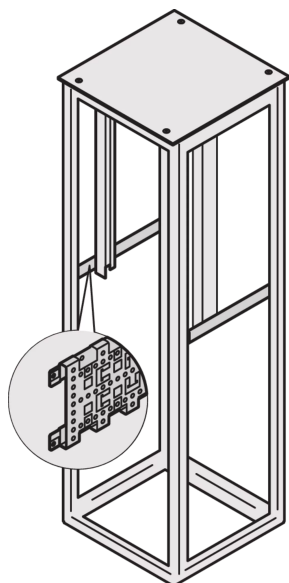

机柜深度支持。可直接安装在 Varistar 框架上，用于管理电缆，提高框架刚度，增加固定点。

## 认证



## 功能

使用电缆扎带和束线带方便电缆布线, 嵌入式机架需要

碳钢, 1.5 mm, 覆铝锌表面

## 技术参数

|       |             |
|-------|-------------|
| 高度:   | 135mm       |
| 产品类型: | 支架          |
| 材料:   | 钢           |
| 搭配:   | Varistar CP |

| Table 1/1 |        |      |     |      |      |      |
|-----------|--------|------|-----|------|------|------|
| 物料号       | 深度     | 包装数量 | 完成  | 机架高度 | 包装单位 | 快速发货 |
| 23130-081 | 600mm  | 2    | 镀锌铝 | 3U   | 对    | No   |
| 23130-365 | 1200mm | 2    | 镀锌铝 | 3U   | 对    | No   |
| 23130-083 | 900mm  | 2    | 镀锌铝 | 3U   | 对    | No   |
| 23130-364 | 1100mm | 2    | 镀锌铝 | 3U   | 对    | No   |
| 23130-082 | 800mm  | 2    | 镀锌铝 | 3U   | 对    | No   |
| 23130-084 | 1000mm | 2    | 镀锌铝 | 3U   | 对    | No   |

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE