


适用连接器的 Z 形轨道, EN 60603-2, DIN 41612

适用连接器的 Z 形轨道, 符合 EN 60603-2 (DIN 41612) 标准。

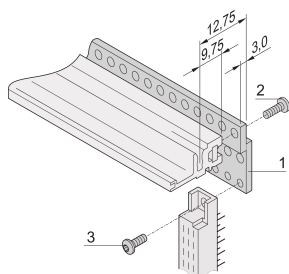

认证



功能

Z 型轨用螺栓固定在插箱上, 以安装连接器 (后水平轨道 ST 型), 插入螺纹嵌件)

适用于符合 EN 60603 - 2 (DIN 41612) 的连接器

铝挤压件, 阳极氧化

技术参数

材料:	铝
完成:	阳极氧化
搭配:	插箱; 仪器箱
产品系列:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
产品类型:	Z 形导轨

Table 1/1

物料号	机架宽度	包装数量	长度	认证	快速发货
30822-170	8HP	1	40.64mm		No

物料号	机架宽度	包装数量	长度	认证	快速发货
30822-033	28HP	1	142.24mm	RoHS	No
30822-047	42HP	1	213.36mm	RoHS	No
30822-065	60HP	1	304.8mm	RoHS	No
30822-089	84HP	1	426.72mm	RoHS	No
30822-166	4HP	1	20.32mm	RoHS	No

其他产品详情

将 Z 形轨道安装在水平轨道上需要螺纹插件和内梅花盘头螺钉；请单独订购。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE