

401 Clevis Hanger



认证



功能

Recommended for the suspension of stationary non-insulated pipe lines

Flared edges help prevent sharp surfaces from coming into contact with the pipe (1/2" to 2" pipe sizes)

Clevis bottom pivots to allow pipe to be fed from either direction

Conforms with Federal Specification WW-H-171 (Type 1), Manufacturers Standardization Society (MSS) SP-58 (Type 1)

技术参数

材料: 钢


Table 1/2

物料号	订货号	完成	NB/DN	外径 (OD)	杆尺寸 (RS)	A
4010050EG	179398	Electrogalvanized, 预镀锌	15	21 mm	M10	59 mm
4010075EG	179399	Electrogalvanized, 预镀锌	20	27 mm	M10	64 mm

物料号	订货号	完成	NB/DN	外径 (OD)	杆尺寸 (RS)	A
4010100EG	179420	Electrogalvanized, 预镀锌	25	34 mm	M10	71 mm
4010125EG	179421	Electrogalvanized, 预镀锌	32	43 mm	M10	80 mm
4010150EG	179422	Electrogalvanized, 预镀锌	40	48 mm	M10	94 mm
4010200EG	179423	Electrogalvanized, 预镀锌	50	60 mm	M10	110 mm
4010250EG	179424	Electrogalvanized, 预镀锌	65	76 mm	M12	134 mm
4010300EG	179425	Electrogalvanized, 预镀锌	80	89 mm	M12	154 mm
4010350EG	179521	Electrogalvanized, 预镀锌	90	101.6 mm	M12	172 mm
4010400EG	179426	Electrogalvanized, 预镀锌	100	114 mm	M16	189 mm
4010500EG	179427	Electrogalvanized, 预镀锌	125	140 mm	M16	231 mm
4010600EG	179428	Electrogalvanized, 预镀锌	150	165 mm	M20	268 mm
4010800EG	179429	Electrogalvanized, 预镀锌	200	219 mm	M20	356 mm
4011000EG	179430	Electrogalvanized, 预镀锌	250	273 mm	M20	419 mm
4011200EG	179431	Electrogalvanized, 预镀锌	300	324 mm	M20	473 mm

Table 2/2					
物料号	订货号	B	C	静态负载	认证
4010050EG	179398	29 mm	9 mm	2700N	UL, cUL, ITB
4010075EG	179399	32 mm	9 mm	2700N	UL, cUL, ITB

物料号	订货号	B	C	静态负载	认证
4010100EG	179420	35 mm	9 mm	2700N	UL, cUL, ITB
4010125EG	179421	40 mm	9 mm	2700N	UL, cUL, ITB
4010150EG	179422	53 mm	17 mm	2700N	UL, cUL, ITB
4010200EG	179423	63 mm	22 mm	2700N	UL, cUL, ITB
4010250EG	179424	78 mm	25 mm	5000N	UL, cUL, ITB
4010300EG	179425	90 mm	29 mm	5000N	UL, cUL, ITB
4010350EG	179521	101 mm	34 mm	5000N	UL, cUL
4010400EG	179426	111 mm	35 mm	5000N	UL, cUL, ITB
4010500EG	179427	130 mm	41 mm	6400N	UL, cUL, ITB
4010600EG	179428	153 mm	48 mm	8600N	UL, cUL, ITB
4010800EG	179429	204 mm	80 mm	8900N	UL, cUL, ITB
4011000EG	179430	230 mm	66 mm	16000N	ITB
4011200EG	179431	258 mm	78 mm	17000N	ITB

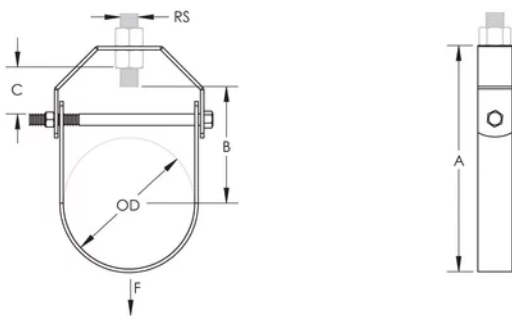

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

