

Branch Line Restraint Pipe Attachment



认证



功能

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

技术参数

完成: 电镀锌

材料: 钢


Table 1/2

物料号	订货号	NB/DN	外径 (OD)	杆尺寸 (RS)	高度 (H)	长度 (L)
-----	-----	-------	---------	----------	--------	--------

CSBBRP0200E G	404480	50	60.3 mm	10, 12	100.3 mm	68.3mm
CSBBRP0125E G	404478	32	42.2 mm	10, 12	82.6 mm	50mm
CSBBRP0150E G	404479	40	48.3 mm	10, 12	88.9 mm	56.1mm
CSBBRP0100E G	404477	25	33.4 mm	10, 12	73.7 mm	41.4mm

Table 2/2		
物料号	订货号	宽度 (W)
CSBBRP0200EG	404480	22.2 mm
CSBBRP0125EG	404478	22.2 mm
CSBBRP0150EG	404479	22.2 mm
CSBBRP0100EG	404477	22.2 mm

图

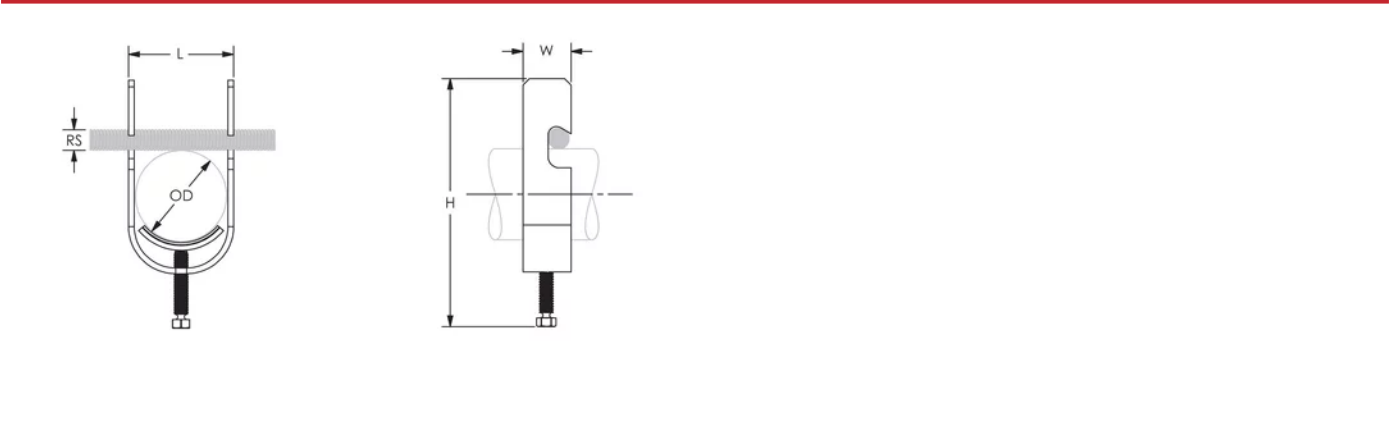

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

