

Easy Universal Sway Brace



认证



Korea Fire Institute

功能

Use for both lateral and longitudinal sway brace applications

Unique slotted holes provide for easy slip-on installation eliminating loose hardware

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

Works with 1" through 2" brace pipes to reduce inventory

Meets NFPA®-13 requirements for seismic sway bracing

技术参数

完成: 电镀锌

Table 1/1

物料号	订货号	材料	NB/DN	A	B	认证
-----	-----	----	-------	---	---	----


CSBEZU0100E G	404356	钢, Cast Iron	25	174.6 mm	25.4 mm	UL, OSHPD, AON Fire Protection, Rigid Seismic, cUL
CSBEZU0150E G	404358	钢, Cast Iron	40	196.9 mm	25.4 mm	AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, ENG, OSHPD, cUL, UL
CSBEZU0125E G	404357	钢, Cast Iron	32	187.4 mm	25.4 mm	cUL, OSHPD, UL, AON Fire Protection, Rigid Seismic
CSBEZU0600E G	404364	钢, Cast Iron	150	346.1 mm	50.8 mm	AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, ENG, OSHPD, cUL, UL
CSBEZU0200E G	404359	钢, Cast Iron	50	206.4 mm	30.2 mm	UL, OSHPD, AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, ENG, cUL
CSBEZU0250E G	404360	钢, Cast Iron	65	225.4 mm	30.2 mm	cUL, OSHPD, UL, AON Fire Protection, Rigid Seismic

CSBEZU0300E G	404361	钢, Cast Iron	80	238.1 mm	30.2 mm	AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, ENG, OSHPD, cUL, UL
CSBEZU0400E G	404362	钢, Cast Iron	100	269.9 mm	38.1 mm	UL, OSHPD, AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, ENG, cUL
CSBEZU0500E G	404363	钢, Cast Iron	125	308 mm	38.1 mm	cUL, OSHPD, UL, AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, ENG

UL Loads (Listed for Restraints)		
Part Number	Lateral Sch 10 Service Pipe	Longitudinal Sch 40 Service Pipe
CSBEZU0100EG	2914 N	2914 N
CSBEZU0125EG	2914 N	2914 N
CSBEZU0150EG	2914 N	2914 N
CSBEZU0200EG	2914 N	NA

UL Loads (Listed for Sway Braces)			
Part Number	Lateral	Longitudinal	Brace Member
	KS D 3507/KS D 3562 Service Pipe	KS D 3507/KS D 3562 Service Pipe	
CSBEZU0200	5338 N	N/A	25A to 32A KS D 3562
CSBEZU0300	7117 N	3025 N	25A to 32A KS D 3562
CSBEZU0400	8896 N	4448 N	25A to 32A KS D 3562
CSBEZU0500	8896 N	4849 N	25A to 32A KS D 3562
CSBEZU0600	8896 N	4849 N	25A to 32A KS D 3562

图

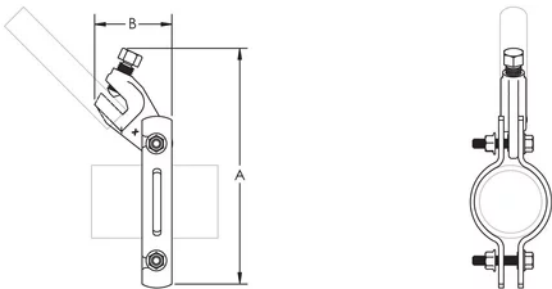

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

