


nVent CADDY Pyramid Equipment Support Post Base

物料号

PEB

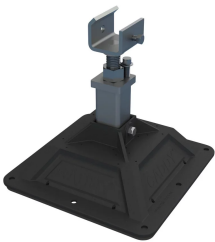

功能

Ideal for use with strut channel type A and U-shaped brackets to create custom equipment supports

Height adjustable

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Hot-dip galvanized and UV stabilized for long lasting performance

产品属性

订货号: 360425

材料: 钢;聚丙烯;聚乙烯

完成: 热浸镀锌

温度: -34 to 54.4 °C

静态负载安全系数: 3:1

高度 (H): 305 - 457 mm


长度 (L): 314mm

宽度 (W): 314 mm
A: 76 mm
表面积: 0.09m ²
单位重量: 4 kg
静态负载: 3340N

其他产品详情

The end user must select and evaluate the strut framing to ensure the custom assembled equipment support can properly support the applied load.

图

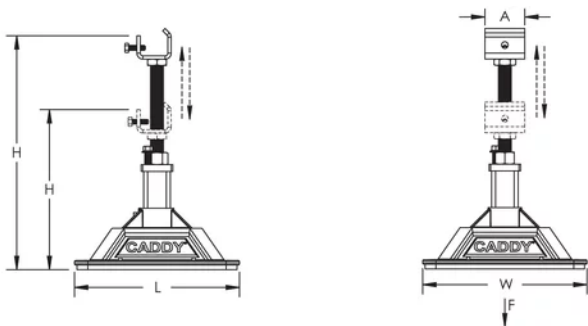

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

