

nVent CADDY Speed Link SLK with Hook, 1.5 mm Wire, 10 m Length

物料号

SLK15L10



认证



功能

Complete system includes wire, locking device and pre-assembled hook end fitting

Hooks to a wide range of nVent CADDY fasteners

Fastens to the building structure or hanging services by looping around and hooking to wire rope

Easy to remove for applications requiring maintenance

Spring latch helps provide secure connection

Insert cable through hole and use bottom side of hook as an end stop

Also available in Y-hook configuration

产品属性

订货号: 196513

材料: 钢;聚丙烯;锌合金

完成: 电镀锌

静态负载安全系数: 5:1

钢丝绳直径: 1.5 mm

符合: SMACNA HVAC-DCS

钢丝绳长度: 10m

A: 48 mm

B: 18 mm

C: 4.5 mm

高度 (H): 55 mm


宽度 (W): 19 mm

厚度 (T): 12.5 mm

角度 (a): 90 ° Max

静态负载: 195N

图

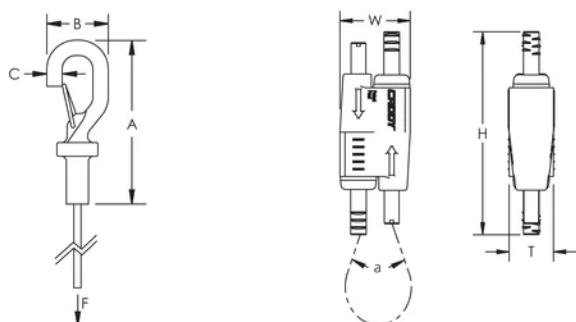

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

