

nVent CADDY Macrofix Insulated M8/M10



认证



功能

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory☒

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

技术参数

颜色: 黑色

完成: 电镀锌

温度: -50 to 110 °C

Table 1/2

物料号	订货号	材料	外径 (OD)	NB/DN	杆尺寸 (RS)	宽度 (W)
MFD015	586001	钢, EPDM-SBR Rubber	11 - 15 mm	8	M8, M10	20 mm
MFD019	586002	钢, EPDM-SBR Rubber	15 - 19 mm	10	M8, M10	20 mm
MFD025	586003	钢, EPDM-SBR Rubber	19 - 25 mm	15	M8, M10	20 mm
MFD031	586004	钢, EPDM-SBR Rubber	25 - 31 mm	20	M8, M10	20 mm
MFD037	586005	钢, EPDM-SBR Rubber	31 - 37 mm	25	M8, M10	20 mm
MFD044	586006	钢, EPDM-SBR Rubber	37 - 44 mm	32	M8, M10	20 mm
MFD050	586007	钢, EPDM-SBR Rubber	44 - 50 mm	40	M8, M10	20 mm
MFD058	586008	钢, EPDM-SBR Rubber	50 - 58 mm		M8, M10	20 mm
MFD068	586009	钢, EPDM-SBR Rubber	58 - 68 mm	50	M8, M10	20 mm
MFD078	586010	钢, EPDM-SBR Rubber	68 - 78 mm	65	M8, M10	23 mm
MFD088	586011	钢, EPDM-SBR Rubber	78 - 88 mm		M8, M10	23 mm
MFD098	586012	钢, EPDM-SBR Rubber	88 - 98 mm	80	M8, M10	23 mm
MFD108	586013	钢, EPDM-SBR Rubber	98 - 108 mm	90	M8, M10	23 mm
MFD118	586014	钢, EPDM-SBR Rubber	108 - 118 mm	100	M8, M10	23 mm
MFD128	586015	钢, EPDM-SBR Rubber	118 - 128 mm		M8, M10	23 mm
MFD138	586016	钢, EPDM-SBR Rubber	128 - 138 mm		M8, M10	23 mm

物料号	订货号	材料	外径 (OD)	NB/DN	杆尺寸 (RS)	宽度 (W)
MFD148	586017	钢, EPDM-SBR Rubber	138 - 148 mm	125	M8, M10	25 mm
MFD160	586018	钢, EPDM-SBR Rubber	150 - 160 mm		M8, M10	25 mm
MFD170	586019	钢, EPDM-SBR Rubber	160 - 170 mm	150	M8, M10	25 mm
MFD200	586020	钢, EPDM-SBR Rubber	190 - 200 mm		M8, M10	27 mm
MFD215	586021	钢, EPDM-SBR Rubber	205 - 215 mm		M8, M10	27 mm
MFD225	586022	钢, EPDM-SBR Rubber	215 - 225 mm	200	M8, M10	27 mm
MFD250	586023	钢, EPDM-SBR Rubber	239 - 250 mm		M8, M10	30 mm
MFD275	586024	钢, EPDM-SBR Rubber	265 - 275 mm	250	M8, M10	30 mm
MFD319	586025	钢, EPDM-SBR Rubber	309 - 319 mm		M8, M10	30 mm

Table 2/2					
物料号	订货号	厚度 (T)	螺钉直径 (Sc)	螺钉长度 (L)	静态负载
MFD015	586001	1 mm	6	17mm	1000N
MFD019	586002	1 mm	6	17mm	1000N
MFD025	586003	1 mm	6	22mm	1000N
MFD031	586004	1 mm	6	22mm	1000N
MFD037	586005	1 mm	6	22mm	1000N
MFD044	586006	1 mm	6	27mm	1000N


物料号	订货号	厚度 (T)	螺钉直径 (Sc)	螺钉长度 (L)	静态负载
MFD050	586007	1.25 mm	6	27mm	1500N
MFD058	586008	1.25 mm	6	27mm	1500N
MFD068	586009	1.25 mm	6	32mm	1500N
MFD078	586010	1.5 mm	6	32mm	2000N
MFD088	586011	1.5 mm	6	32mm	2000N
MFD098	586012	1.75 mm	6	37mm	2500N
MFD108	586013	1.75 mm	6	37mm	2500N
MFD118	586014	1.75 mm	6	37mm	2500N
MFD128	586015	2 mm	6	37mm	3000N
MFD138	586016	2 mm	6	37mm	3000N
MFD148	586017	2 mm	6	37mm	3200N
MFD160	586018	2 mm	6	37mm	3200N
MFD170	586019	2 mm	6	37mm	3200N
MFD200	586020	2.25 mm	6	37mm	3600N
MFD215	586021	2.25 mm	6	37mm	3600N
MFD225	586022	2.25 mm	6	37mm	3600N
MFD250	586023	2.5 mm	6	37mm	4000N

物料号	订货号	厚度 (T)	螺钉直径 (Sc)	螺钉长度 (L)	静态负载
MFD275	586024	2.5 mm	6	37mm	4000N
MFD319	586025	2.5 mm	6	37mm	4000N

其他产品详情

Lining is EPDM rubber.

图

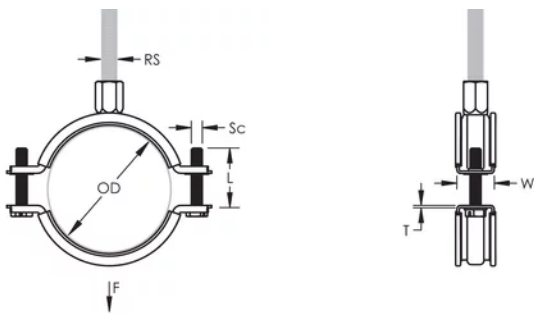

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

