


nVent CADDY Pyramid Equipment Support Kit, 4 Post Base

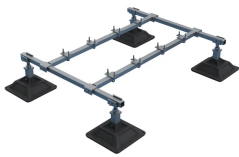

认证



功能

- Kit includes post-base assemblies, frame and equipment-support clamps
- Assembles and adjusts to size and height in minutes by one person with one tool
- Innovative crossbar and equipment-support clamps enable quick assembly
- Integral foam pad provides gentle interface for all roof types
- Hot-dip galvanized and UV stabilized for long lasting performance
- Assembled support can be lifted as one unit and easily relocated

技术参数

Table 1/3

物料号	订货号	材料	完成	温度	高度 (H)	长度 (L)
-----	-----	----	----	----	--------	--------

PEK4B	360426	钢, Polypropylene, Polyethylene	热浸镀锌	-34 to 54.4 °C	305 - 457 mm	1257mm
-------	--------	--------------------------------------	------	----------------	--------------	--------


Table 2/3						
物料号	订货号	后基座 (A)	方形管 (B)	横杆总成 (C)	宽度 (W)	表面积
PEK4B	360426	314 mm x 4 pc	1067 mm x 2 pc	1232 mm x 2 pc	1588 mm	0.36m ²

Table 3/3				
物料号	订货号	单位重量	极限静态负载 (F)	静态负载安全系数
PEK4B	360426	36 kg	4980N	3:1

其他产品详情

Static load must be stable and uniformly distributed across frame.

图

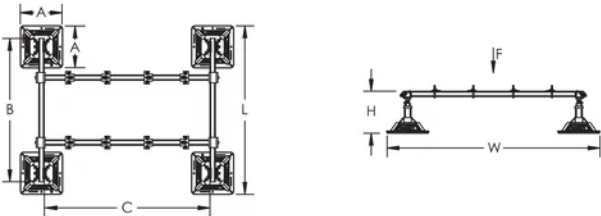

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

