

nVent CADDY Pyramid H-Frame Post Base



功能

Foam or rubber bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Rubber rooftop interface ideal for solar panel array installations

Mounting hardware pre-installed in bases

Hot-dip galvanized and UV stabilized for long lasting performance

Accepts standard strut channels

技术参数

Table 1/3


物料号	订货号	材料	完成	温度	静态负载安全系数	屋顶接口
PHB	360422	钢, Polypropylene, Polyethylene	热浸镀锌	-34 to 54.4 °C	3:1	泡沫

Table 2/3

物料号	订货号	支柱类型	高度 (H)	长度 (L)	宽度 (W)	表面积
PHB	360422	A (41 x 41 mm)	117 mm	314mm	314 mm	0.09m ²

Table 3/3			
物料号	订货号	单位重量	静态负载
PHB	360422	1.8 kg	3335N

图

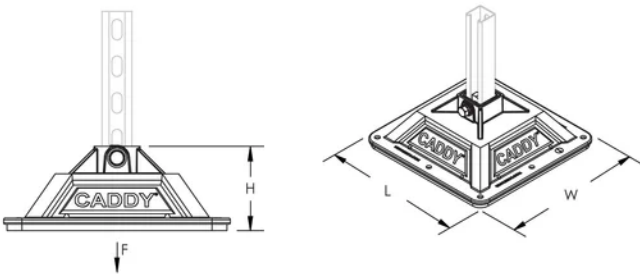

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

