

nVent CADDY Pyramid Universal Support



功能

Captive stainless steel nuts allow for custom attachment methods to the support base including easy attachment of stainless steel strut, threaded rod or other project-specific hardware

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Multiple sizes and load ratings offer the ability to tailor the solution to the application

Includes square holes for creating an H-Frame with a 12" (305 mm) cross support (PBU16 only)

Base is manufactured from UV-stabilized thermoplastic material

技术参数

静态负载安全系数: 3:1

温度: -45 to 65 °C

Table 1/3


物料号	订货号	材料	长度 1 (L1)	长度 2 (L2)	高度 (H)	宽度 (W)
PBU6M	360495	Polyethylene, Polypropylene, 不锈钢 18-8 (EN 1.4305)	140 mm	196 mm	102 mm	150 mm

物料号	订货号	材料	长度 1 (L1)	长度 2 (L2)	高度 (H)	宽度 (W)
PBU10M	360496	Polyethylene, Polypropylene, 不锈钢 18-8 (EN 1.4305)	254 mm	318 mm	102 mm	201 mm
PBU16M	360497	Polyethylene, Polypropylene, 不锈钢 18-8 (EN 1.4305)	406 mm	480 mm	102 mm	201 mm

Table 2/3						
物料号	订货号	螺纹尺寸 (TS)	孔数量	A	B	表面积
PBU6M	360495	M10	3	114 mm	57 mm	26452mm ²
PBU10M	360496	M10	2	218 mm		59355mm ²
PBU16M	360497	M10	2	165 mm		91613mm ²

Table 3/3		
物料号	订货号	静态负载
PBU6M	360495	1330N
PBU10M	360496	4450N
PBU16M	360497	6670N

图

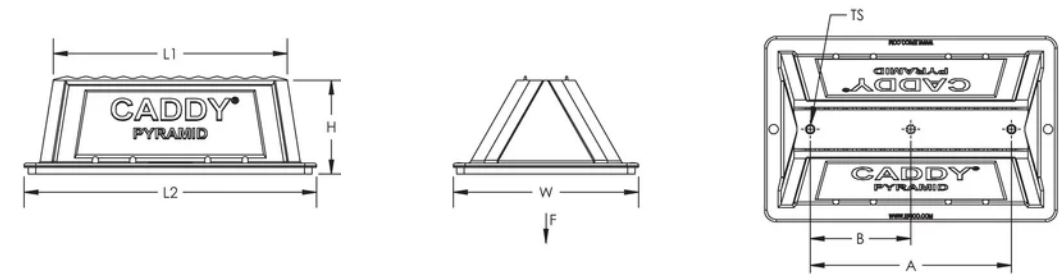

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

