

nVent CADDY Speed Link SLK with Angle Bracket



认证



功能

Complete system includes wire, locking device and pre-assembled angle bracket end fitting

Ideal for attaching to concrete, steel or wood surfaces

Simple alternative to jack chain and additional hardware

技术参数

静态负载安全系数: 5:1

完成: 电镀锌

符合: SMACNA HVAC-DCS

Table 1/3


物料号	订货号	材料	钢丝绳直径	钢丝绳长度	A	孔尺寸 (HS)
-----	-----	----	-------	-------	---	----------

SLK3L10AB	196716	Steel, 锌合金, Polypropylene	3 mm	10m	22.6 mm	7.1 mm
SLK2L3AB	196530	Steel, 锌合金, Polypropylene	2 mm	3m	22.6 mm	7.1 mm
SLK2L5AB	196531	Steel, 锌合金, Polypropylene	2 mm	5m	22.6 mm	7.1 mm

Table 2/3						
物料号	订货号	高度 (H)	宽度 (W)	厚度 (T)	角度 (a)	静态负载
SLK3L10AB	196716	62 mm	24 mm	16 mm	90 ° Max	890N
SLK2L3AB	196530	55 mm	19 mm	12.5 mm	90 ° Max	440N
SLK2L5AB	196531	55 mm	19 mm	12.5 mm	90 ° Max	440N

Table 3/3		
物料号	订货号	认证
SLK3L10AB	196716	
SLK2L3AB	196530	ITB, UL, cUL
SLK2L5AB	196531	ITB, UL, cUL

图

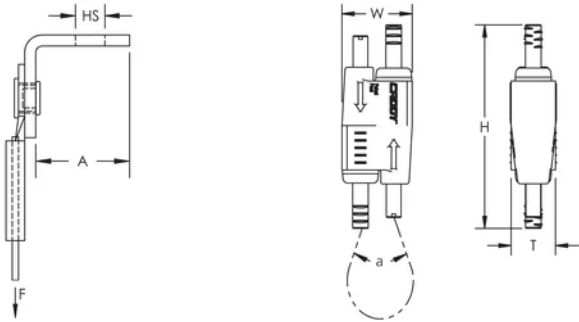

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

