

nVent CADDY Speed Link SLK with Hook



认证



功能

Complete system includes wire, locking device and pre-assembled hook end fitting

Hooks to a wide range of nVent CADDY fasteners

Fastens to the building structure or hanging services by looping around and hooking to wire rope

Easy to remove for applications requiring maintenance

Spring latch helps provide secure connection

Insert cable through hole and use bottom side of hook as an end stop

Also available in Y-hook configuration

技术参数

静态负载安全系数: 5:1

完成: 电镀锌

符合: SMACNA HVAC-DCS

Table 1/3

物料号	订货号	材料	钢丝绳直径	钢丝绳长度	A	B
SLK15L1	196508	Steel, Polypropylene, 锌合金	1.5 mm	1m	48 mm	18 mm
SLK15L10	196513	Steel, Polypropylene, 锌合金	1.5 mm	10m	48 mm	18 mm
SLK15L2	196509	Steel, Polypropylene, 锌合金	1.5 mm	2m	48 mm	18 mm
SLK15L3	196510	Steel, Polypropylene, 锌合金	1.5 mm	3m	48 mm	18 mm
SLK15L5	196511	Steel, Polypropylene, 锌合金	1.5 mm	5m	48 mm	18 mm
SLK2L1	196537	Steel, Polypropylene, 锌合金	2 mm	1m	57 mm	22 mm
SLK2L10	196542	Steel, Polypropylene, 锌合金	2 mm	10m	57 mm	22 mm
SLK2L2	196538	Steel, Polypropylene, 锌合金	2 mm	2m	57 mm	22 mm
SLK2L3	196539	Steel, Polypropylene, 锌合金	2 mm	3m	57 mm	22 mm
SLK2L5	196540	Steel, Polypropylene, 锌合金	2 mm	5m	57 mm	22 mm
SLK3L10	196705	Steel, Polypropylene, 锌合金	3 mm	10m	57.6 mm	23.2 mm
SLK3L2	196701	Steel, Polypropylene, 锌合金	3 mm	2m	57.6 mm	23.2 mm


物料号	订货号	材料	钢丝绳直径	钢丝绳长度	A	B
SLK3L3	196702	Steel, Polypropylene, 锌合金	3 mm	3m	57.6 mm	23.2 mm
SLK3L5	196703	Steel, Polypropylene, 锌合金	3 mm	5m	57.6 mm	23.2 mm

Table 2/3

物料号	订货号	C	高度 (H)	宽度 (W)	厚度 (T)	角度 (a)
SLK15L1	196508	4.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L10	196513	4.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L2	196509	4.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L3	196510	4.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK15L5	196511	4.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L1	196537	5.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L10	196542	5.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L2	196538	5.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L3	196539	5.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK2L5	196540	5.5 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK3L10	196705	6.1 mm	62 mm	24 mm	16 mm	90 ° Max
SLK3L2	196701	6.1 mm	62 mm	24 mm	16 mm	90 ° Max
SLK3L3	196702	6.1 mm	62 mm	24 mm	16 mm	90 ° Max

物料号	订货号	C	高度 (H)	宽度 (W)	厚度 (T)	角度 (a)
SLK3L5	196703	6.1 mm	62 mm	24 mm	16 mm	90 ° Max

Table 3/3			
物料号	订货号	静态负载	认证
SLK15L1	196508	195N	SMACNA, cUL, UL
SLK15L10	196513	195N	UL, SMACNA, cUL
SLK15L2	196509	195N	SMACNA, cUL, UL
SLK15L3	196510	195N	SMACNA, UL, cUL
SLK15L5	196511	195N	SMACNA, cUL, UL
SLK2L1	196537	440N	cUL, UL, SMACNA
SLK2L10	196542	440N	SMACNA, cUL, UL
SLK2L2	196538	440N	SMACNA, cUL, UL
SLK2L3	196539	440N	SMACNA, cUL, UL
SLK2L5	196540	440N	SMACNA, cUL, UL
SLK3L10	196705	890N	SMACNA
SLK3L2	196701	890N	SMACNA
SLK3L3	196702	890N	SMACNA
SLK3L5	196703	890N	SMACNA

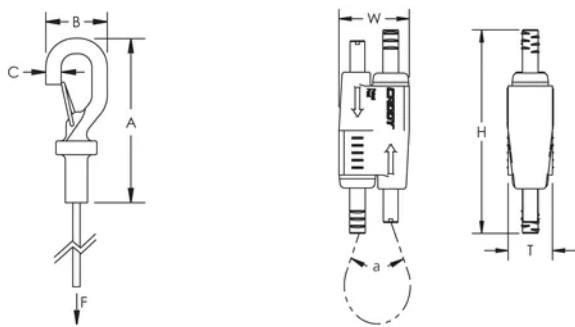

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

