

nVent CADDY Speed Link SLK with Threaded Stud End



认证



功能

Complete system includes wire, locking device and pre-assembled threaded stud end fitting

Attaches to structures with threaded anchors or devices with threaded hole

Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

技术参数

静态负载安全系数:	5:1
完成:	电镀锌
材料:	钢;聚丙烯;锌合金
符合:	SMACNA HVAC-DCS


Table 1/2

物料号	订货号	钢丝绳直径	钢丝绳长度	杆尺寸 (RS)	螺钉长度 (L)	高度 (H)
-----	-----	-------	-------	----------	----------	--------

SLK2L5SEM8	196563	2 mm	5m	8	45mm	55 mm
SLK2L3SEM8	196561	2 mm	3m	8	45mm	55 mm
SLK3L5SEM10	196720	3 mm	5m	10	45mm	62 mm
SLK3L2SEM10	196718	3 mm	2m	10	45mm	62 mm
SLK3L3SEM10	196719	3 mm	3m	10	45mm	62 mm

Table 2/2						
物料号	订货号	宽度 (W)	厚度 (T)	角度 (a)	静态负载	认证
SLK2L5SEM8	196563	19 mm	12.5 mm	90 ° Max	440N	UL, cUL
SLK2L3SEM8	196561	19 mm	12.5 mm	90 ° Max	440N	cUL, UL
SLK3L5SEM10	196720	24 mm	16 mm	90 ° Max	890N	
SLK3L2SEM10	196718	24 mm	16 mm	90 ° Max	890N	
SLK3L3SEM10	196719	24 mm	16 mm	90 ° Max	890N	

图

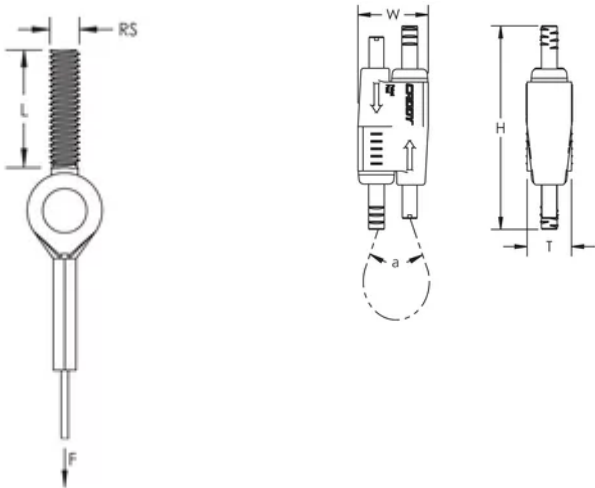

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

