

Quick Grip Lateral Sway Brace



The Quick Grip Lateral Brace, part of the nVent CADDY line of fire sprinkler bracing systems from nVent, is designed to help simplify installations when bracing service pipe for seismic or other catastrophic events. It features an innovative design for quick attachment of brace pipe to service pipe saving time and money.

认证



功能

Easy two-step installation eliminates extra trips between structure and service pipe

Works with 1" and 1 1/4" (25 mm and 32 mm) brace pipes to reduce inventory

Yellow tips provide a visual indicator that the bolts have been properly torqued

Easy installation with an impact wrench from the bottom side of the clamp

Meets NFPA®-13 requirements for seismic sway bracing

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

技术参数

完成: 电镀锌

材料: 钢


Table 1/1

物料号	订货号	NB/DN	高度 (H)	宽度 (W)	认证
-----	-----	-------	--------	--------	----

CSBQG0250MEG	404475	65	138.10 - 148.6 mm	172 mm	FM Approved, Seismic, AON Fire Protection, Rigid Seismic
CSBQG0300EG	404469	80	155.00 - 165.5 mm	190 mm	AON Fire Protection, Rigid Seismic, OSHPD, UL, FM Approved, Seismic, cUL
CSBQG0400EG	404470	100	180.40 - 190.9 mm	222 mm	OSHPD/HCAI, UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic, cUL
CSBQG0600EG	404472	150	235.50 - 244.9 mm	298 mm	cUL, UL, FM Approved, Seismic, OSHPD/HCAI, AON Fire Protection, Rigid Seismic
CSBQG0800EG	404473	200	289.2 - 300 mm	351.8 mm	AON Fire Protection, Rigid Seismic, OSHPD, UL, FM Approved, Seismic, cUL

FM Loads					
Part Number	Service Pipe Schedule	Lateral			
		Horizontal Capacity per Installation Angle from Vertical			
		30°- 44°	45°- 59°	60°- 74°	75°- 90°
CSBQG0250EG/ CSBQG0250MEG	EN10255 L (Lightwall)	6270 N	8895 N	10900 N	12190 N
	EN10255 M (10)	6270 N	8895 N	10900 N	12190 N
	EN10255 H (40)	6270 N	8895 N	10900 N	12190 N
CSBQG0300EG	EN10255 L (Lightwall)	5295 N	7475 N	9163 N	10230 N
	EN10255 M (10)	5295 N	7475 N	9163 N	10230 N
	EN10255 H (40)	5295 N	7475 N	9163 N	10230 N
CSBQG0400EG	EN10255 L (Lightwall)	5295 N	7475 N	9163 N	10230 N
	EN10255 M (10)	5295 N	7475 N	9163 N	10230 N
	EN10255 H (40)	5295 N	7475 N	9163 N	10230 N
CSBQG0600EG	EN10255 L (Lightwall)	3870 N	5470 N	6715 N	7515 N
	EN10255 M (10)	3870 N	5470 N	6715 N	7515 N
	EN10255 H (40)	4315 N	6095 N	7475 N	8320 N
CSBQG0800EG	4.8 mm (Wall Thickness)	3515 N	4940 N	6050 N	6760 N
	EN10255 H (40)	3515 N	4940 N	6050 N	6760 N

图

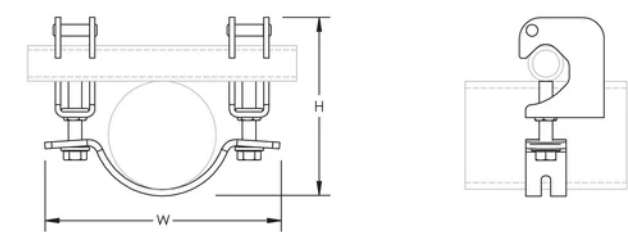

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

