

Snap Close Conduit/Pipe Clamp



The nVent CADDY Snap Close Conduit Clamps (M-Series) are a fast and efficient method to secure conduit branch circuits for electrical installations. The M-Series is designed to provide positional consistency in application by eliminating conduit offset as well as maintain spacing entering electrical boxes. Increase installation efficiency by utilizing our comprehensive conduit range for your next electrical project.

认证



功能

May be used for either vertical or horizontal installations

Eliminates need for offset bending conduit

Finger closure, no tools required

Locking design has greater resistance to twisting loads and is stronger than any on the market

Low profile locking tabs and smooth gripping dimples remove the possibility of scrapes

812M and 16M feature double tabs to center conduit, increase range and holding power and prevent conduit from sliding

技术参数

完成: nVent CADDY 铠装


材料: 弹簧钢

Table 1/1

物料号	订货号	外径 (OD)	孔尺寸 (HS)	孔类型	静态负载 1 (F1)	静态负载 2 (F2)
-----	-----	---------	----------	-----	-------------	-------------

812M	177130	18 - 30 mm	7 mm	普通	440N	110N
20M	170110	35 - 42 mm	7 mm	普通	440N	110N
24M	170120	42 - 50 mm	7 mm	普通	440N	110N
32M	170130	50 - 60 mm	7 mm	普通	440N	110N
6M	170790	14 - 18 mm	7 mm	普通	440N	110N
16M	170100	23.4 - 35 mm	7 mm	普通	440N	110N

图

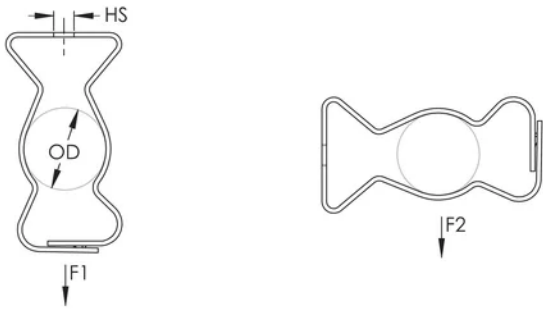

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

