


Steel Flange Adapter Assembly

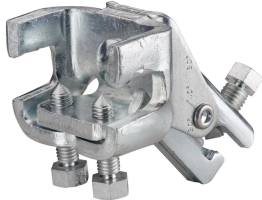

认证



功能

Steel Flange Adapter and Universal Structural Bracket are preassembled, limiting work required in the field

Installs on top or bottom flange of I-beams or bar joists

Low profile easily fits between metal deck and steel structure

Thumb spring retainer allows for ease of positioning

Integrated angle gauge easily displays brace member angle of installation

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

Works with 1" through 2" brace pipes to reduce inventory

Meets NFPA® 13 as pre-qualified for seismic applications

FM Approved with the following brace members: 1-2 in Sch40 Pipe

FM Specification Tested with the following brace members: 1-2 in Sch40 Pipe

技术参数


Table 1/2						
物料号	订货号	材料	完成	法兰厚度 (FT)	高度 (H)	宽度 (W)
CSBS1A	404505	钢	电镀锌	6 - 19 mm	67 mm	92 mm

Table 2/2						
物料号	订货号	角度 (a)	A	B	C	D
CSBS1A	404505	45 °	105 mm	33 mm	65 mm	23 mm

UL Loads			
Part Number	Flange Thickness	Brace Member	Load Rating
CSBS1A	6 - 8 mm	DN25 - DN50 Sch. 40 NPS	6672 N
	8 - 19 mm		7561 N

FM Loads								
Part Number	Horizontal Capacity per Installation Angle from Vertical							
	Perpendicular to Structure				Parallel to Structure			
	30°- 44°	45°- 59°	60°- 74°	75°- 90°	30°- 44°	45°- 59°	60°- 74°	75°- 90°
CSBS1A	3780 N	7910 N	12320 N	12630 N	3910 N	6360 N	8980 N	10720 N

图

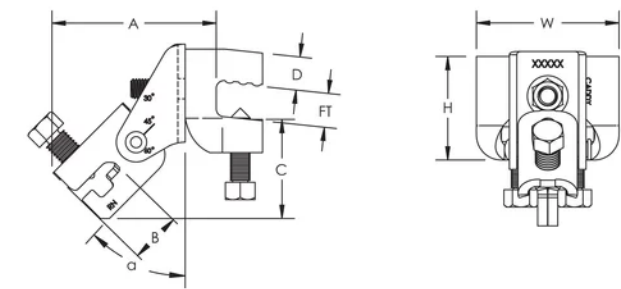

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

